

SMA/M-N/M RG-402 (FEP Jacket) FLEXIBLE CABLE, 18GHz

SCA1814-0105-XX


SPECIFICATIONS

CABLE ASSEMBLY:
VSWR: 1.2:1 @ < 18GHz TYPICAL


RAW CABLE: RG402(FEP Jacket)
TYPICAL LOSS (EXCLUDING CONNECTORS)
@400MHz 0.14dB/ft
@1GHz 0.23 dB/ft
@3GHz 0.39 dB/ft
@5GHz 0.52 dB/ft
@10GHz 0.80 dB/ft
@18GHz 1.10 dB/ft

CONNECTORS:
STAINLESS STEEL
SMA torque 8-in-lbs
CONTACTS Au PLATING
INTERFACE: MIL-STD-348A

OP TEMP: -45-110°C
ROHS COMPLIANT

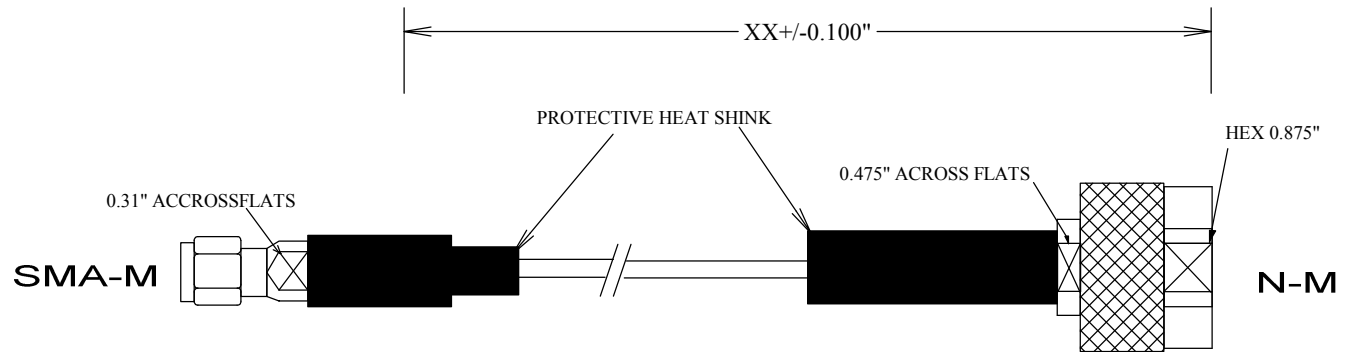

MEASUREMENTS BELOW ARE TYPICAL

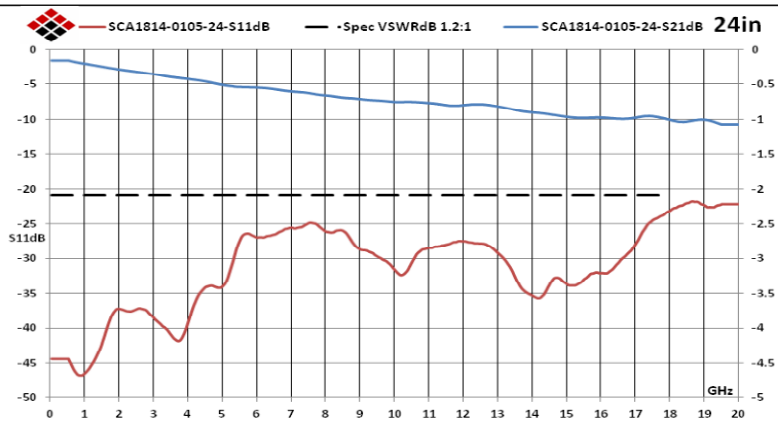

ALL DIMENSIONS IN inches(MM) Typical

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

SMA/M-N/M RG-402 (FEP Jacket) FLEXIBLE CABLE, 18GHz

SIZE

A

CAGE CODE

3FKR5

DWG NO

SCA1814-0105-XX

REV

--

SCALE

SHEET