

N/M-N/M RG-402 (Urethane Jacket) FLEXIBLE CABLE, 18GHz

SCA1815-0505-XX

SPECIFICATIONS

CABLE ASSEMBLY:

VSWR: 1.2:1 @ < 18GHz TYPICAL

RAW CABLE: RG-402 (Urethane Jacket)

TYPICAL LOSS (EXCLUDING CONNECTORS)

@0.4GHz: 0.08dB/Ft

@1GHz: 0.13dB/Ft

@3GHz: 0.23dB/Ft

@5GHz: 0.3dB/Ft

@10GHz: 0.45dB/Ft

@18GHz: 0.64dB/Ft


CONNECTORS:

BNC: BRASS


CONTACTS Au PLATING

INTERFACE: MIL-STD-348A

OP TEMP: -55-110°C

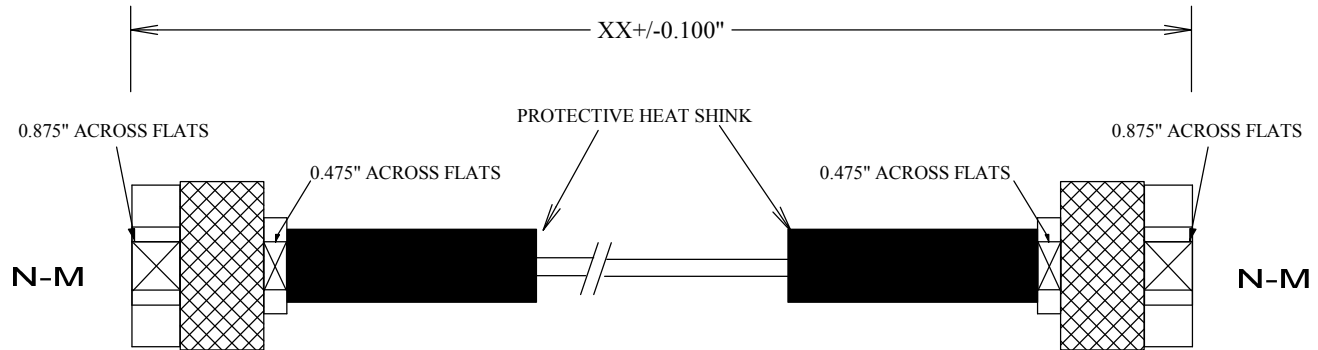

MEASUREMENTS BELOW ARE TYPICAL

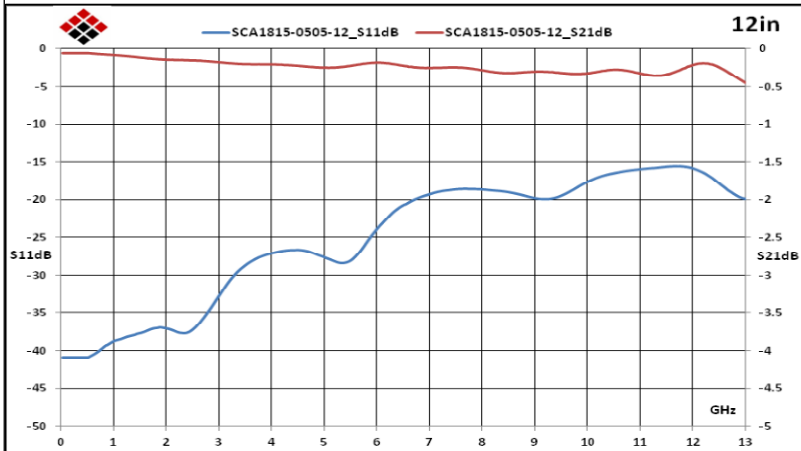

ALL DIMENSIONS IN inches(MM) Typical

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

N/M-N/M RG-402 (Urethane Jacket)
FLEXIBLE CABLE, 18GHz

SIZE

A

CAGE CODE

3FKR5

DWG NO

SCA1815-0505-XX

REV

--

SCALE

SHEET