

N/M-N/M FLEXIBLE CABLES 6GHZ LMR400PLENUM

SCB110519-XX

SPECIFICATIONS


CABLE ASSEMBLY:
VSWR:1.2:1 @ < 6GHZ TYPICAL

RAW CABLE: LMR400PLENUM
TYPICAL LOSS (EXCLUDING CONNECTORS)


@1GHz: 0.041 DB/FT
@2GHz: 0.06DB/FT
@4GHz: 0.087db/ft
@6GHz: 0.11 DB/FT
@8GHz: 0.13 DB/FT

CONNECTORS: BRASS
CONTACTS Au PLATING
INTERFACE: MIL-STD-348A

OP TEMP: -55-110°C

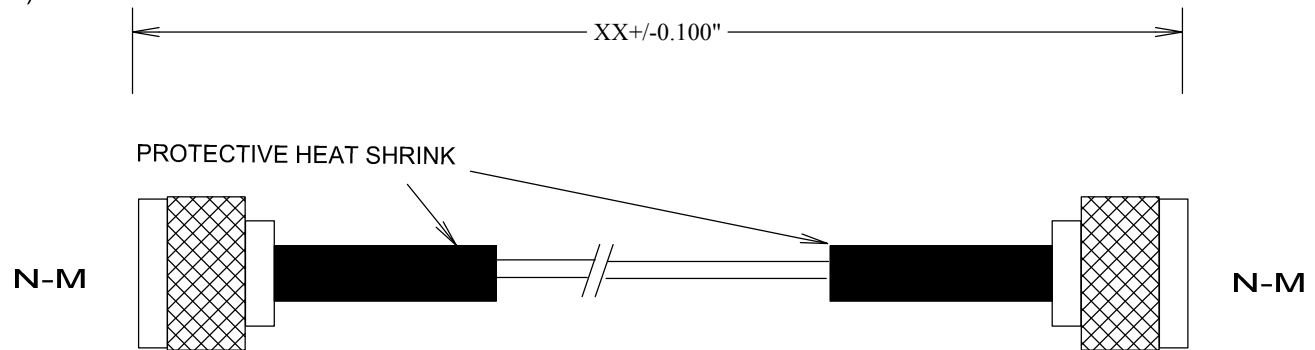

MEASUREMENTS BELOW ARE TYPICAL

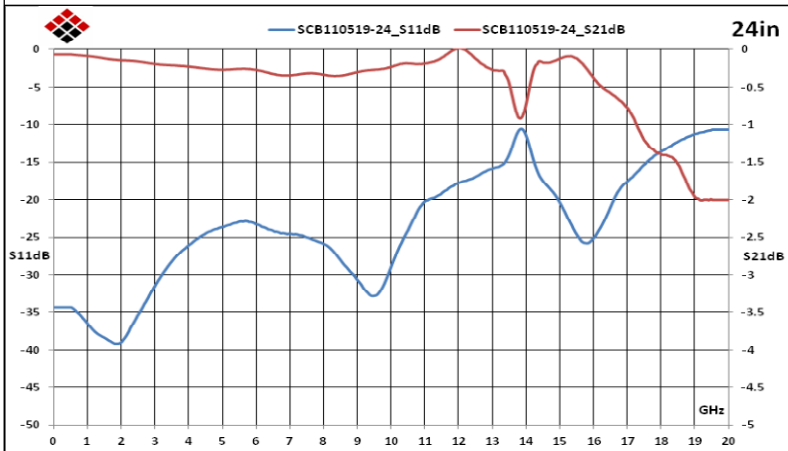

ALL DIMENSIONS IN inches(MM) Typical

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

N/M-N/M FLEXIBLE CABLES
6GHZ LMR400PLENUM

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SCB110519-XX	--
SCALE	SHEET		