

N/M - N/M- FLEXIBLE CABLES 6GHZ LMR240PLENUM

SCB111800-XX

SPECIFICATIONS

CABLE ASSEMBLY:

VSWR:1.2:1 @ < 6GHZ TYPICAL

RAW CABLE: LMR240PLENUM

TYPICAL LOSS (EXCLUDING CONNECTORS)

@1GHz: 0.081 DB/FT

@2GHz: 0.116 DB/FT

@6GHz: 0.205 DB/FT


@8GHz: 0.238 DB/FT

CONNECTORS: BRASS


CONTACTS Au PLATING

INTERFACE: MIL-STD-348A

OP TEMP: -55-110°C

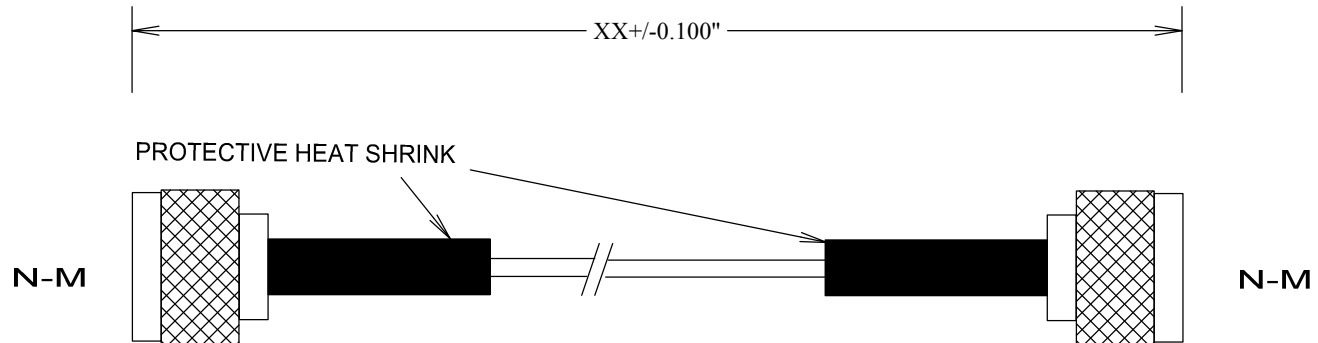

MEASUREMENTS BELOW ARE TYPICAL

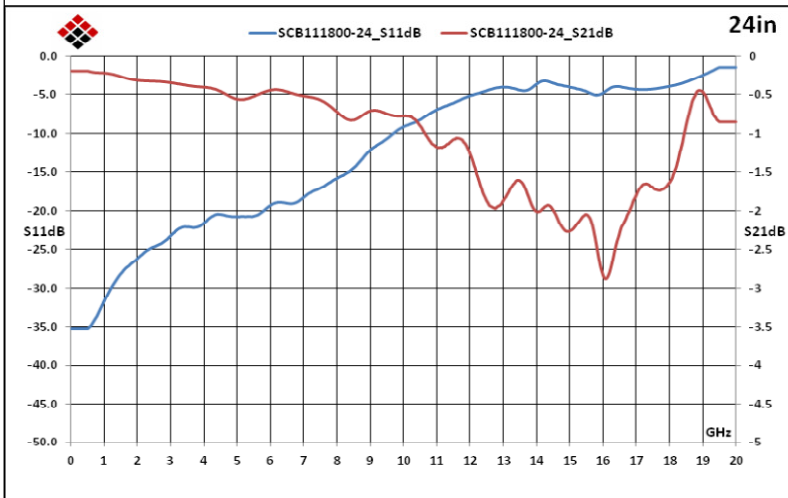

ALL DIMENSIONS IN inches(MM) Typical

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

N/M - N/M- FLEXIBLE CABLES 6GHZ
LMR240PLENUM

SIZE

A

CAGE CODE

3FKR5

DWG NO

SCB111800-XX

REV

--

SCALE

SHEET