

SMA/M-SMA/M FLEXIBLE CABLES RG142 6GHZ

SCB15170-XX


SPECIFICATIONS

CABLE ASSEMBLY:
VSWR:1.2:1 @ < 2GHZ TYPICAL


RAW CABLE: RG142
TYPICAL LOSS (EXCLUDING CONNECTORS)
0.1GHz 0.04 dB/ft
1GHz 0.13 dB/ft
3GHz 0.24 dB/ft
6GHz 0.35 dB/ft

CONNECTORS:
SMA: BRASS: torque 5-in-lbs
CONTACTS Au PLATING 30uin
INTERFACE: MIL-STD-348A

OP TEMP: -45-85°C
ROHS COMPLIANT

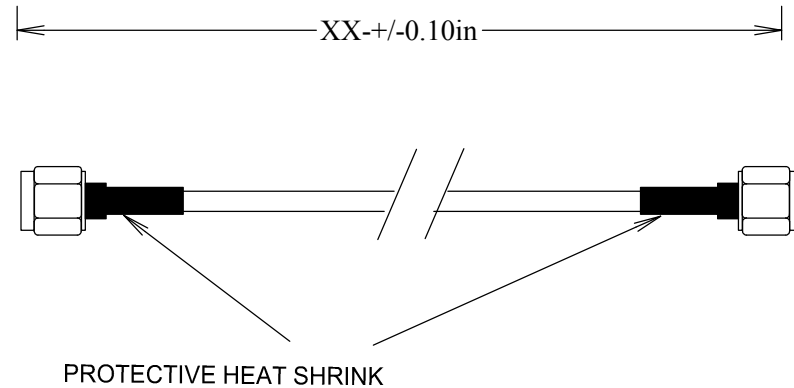

MEASUREMENTS BELOW ARE TYPICAL

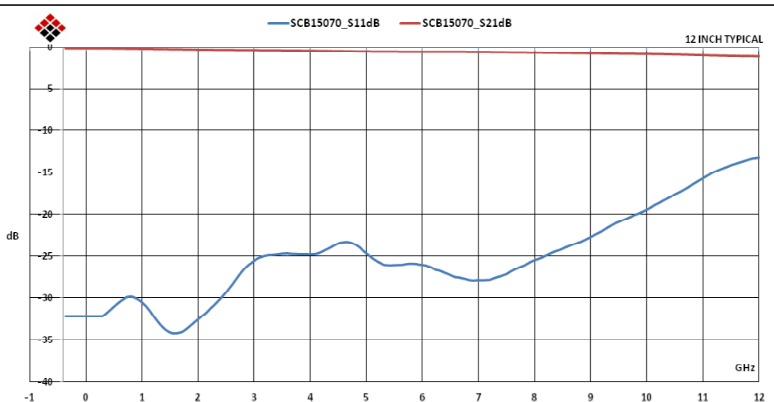

ALL DIMENSIONS IN inches(MM) Typical

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

SMA/M-SMA/M FLEXIBLE CABLES RG142 6GHZ

SIZE

A

CAGE CODE

3FKR5

DWG NO

SCB15170-XX

REV

A

SCALE

SHEET