

2.92 DIRECTIONAL COUPLERS 6-26 GHZ

MC0626


SPECIFICATIONS

ELECTRICAL:

FREQUENCY: 6-26 GHZ
 VSWR 1.55:1 MAX
 POWER CW: 20 WATTS
 COUPLING: 20 DB +/- 1 DB
 COUPLING FLATNESS: +/- 0.80 DB MAX
 INSERTION LOSS: 0.70 DB MAX
 IMPEDANCE: 50 OHMS

ENVIRONMENTAL:

TEMP: -55 C TO +125 C

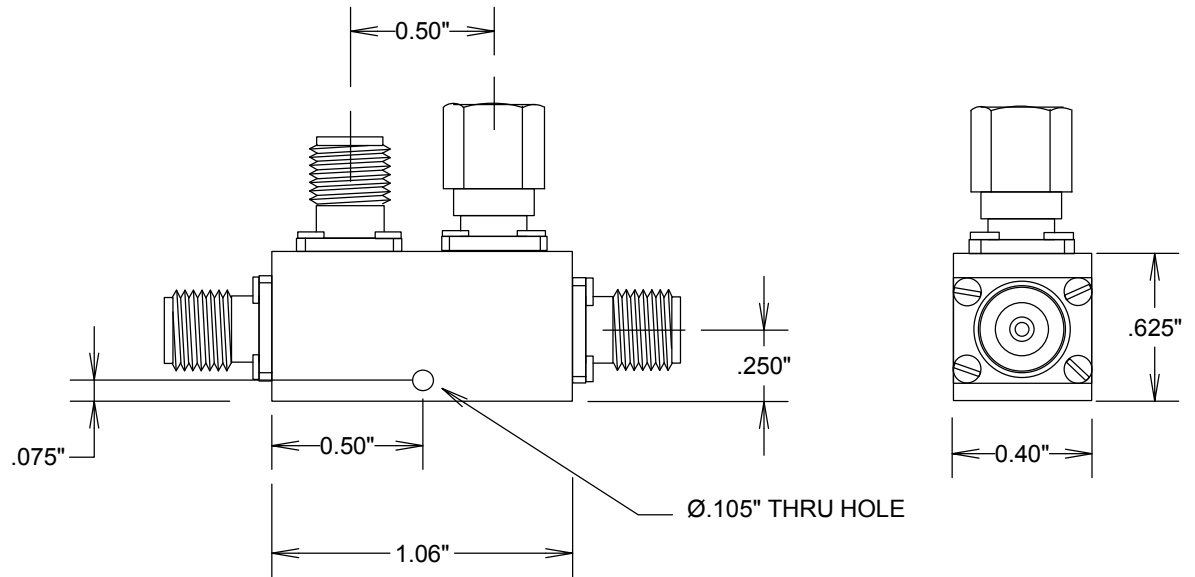

| | | | | | |
|----------|--------------|--------|---------------|---|-----|
| | | | | FAIRVIEW MICROWAVE INC. | |
| | | | | ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM | |
| | | | | TITLE | |
| | | | | 2.92 DIRECTIONAL COUPLERS 6-26 GHZ | |
| SIZE | CAGE CODE | DWG NO | MC0626 | | REV |
| A | 3FKR5 | | | | |
| SCALE | | | SHEET | | |