

# SMA DIRECTIONAL COUPLER .5-2GHZ

MC2024

## SPECIFICATIONS

### ELECTRICAL:


FREQUENCY: .5-2 GHZ  
 VSWR 1.25:1 MAX  
 POWER CW: 50 WATTS  
 POWER PEAK: 3KW  
 DIRECTIVITY: 20 DB MIN  
 TRUE LOSS: THRU: 06DB: 2.0DB  
 TRUE LOSS: THRU: 10DB: 0.9DB  
 TRUE LOSS: THRU: 20DB: 0.4DB  
 TRUE LOSS: THRU: 30DB: 0.4DB  
 IMPEDANCE: 50 OHMS

### CONNECTORS:

BODY: Au PLATED BRASS  
 CONTACTS: AU PLATED

### ENVIRONMENTAL:

TEMP: -55 C TO +125 C

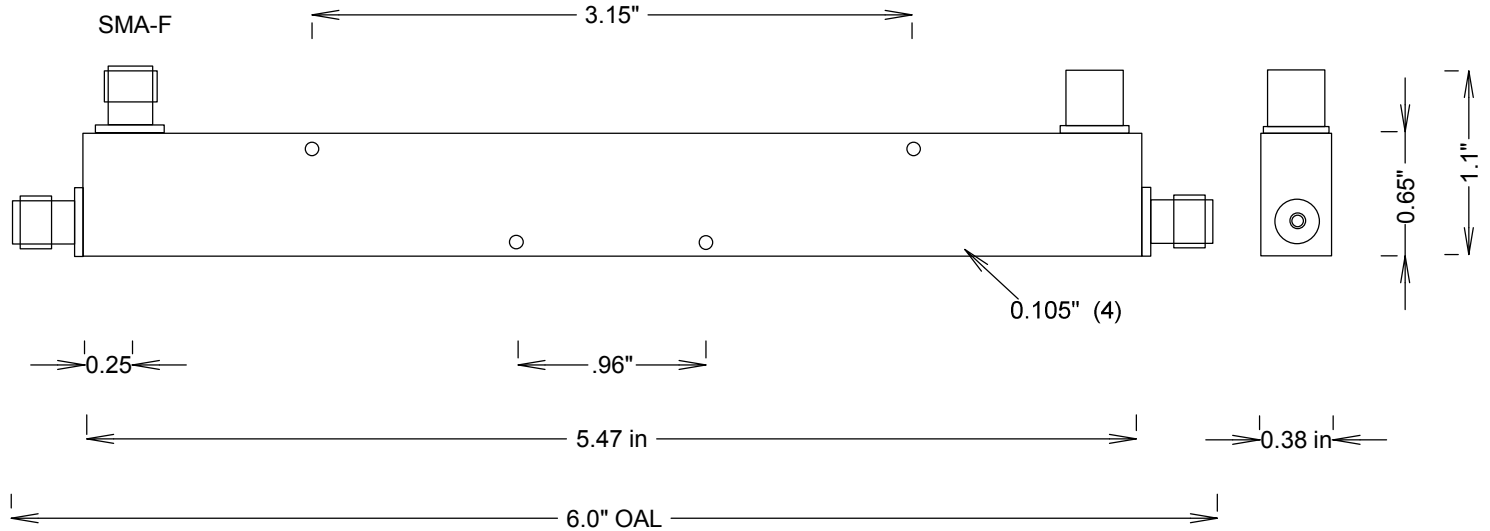

**FAIRVIEW MICROWAVE INC.**

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

**SMA DIRECTIONAL COUPLER .5-2GHZ**

SIZE	CAGE CODE	DWG NO	REV
<b>A</b>	<b>3FKR5</b>	<b>MC2024</b>	
SCALE	SHEET		