

SMA DIRECTIONAL COUPLER .5-2GHZ

MC2024

SPECIFICATIONS

ELECTRICAL:


FREQUENCY: .5-2 GHZ
 VSWR 1.25:1 MAX
 POWER CW: 50 WATTS
 POWER PEAK: 3KW
 DIRECTIVITY: 20 DB MIN
 TRUE LOSS: THRU: 06DB: 2.0DB
 TRUE LOSS: THRU: 10DB: 0.9DB
 TRUE LOSS: THRU: 20DB: 0.4DB
 TRUE LOSS: THRU: 30DB: 0.4DB
 IMPEDANCE: 50 OHMS

CONNECTORS:

BODY: Au PLATED BRASS
 CONTACTS: AU PLATED

ENVIRONMENTAL:

TEMP: -55 C TO +125 C

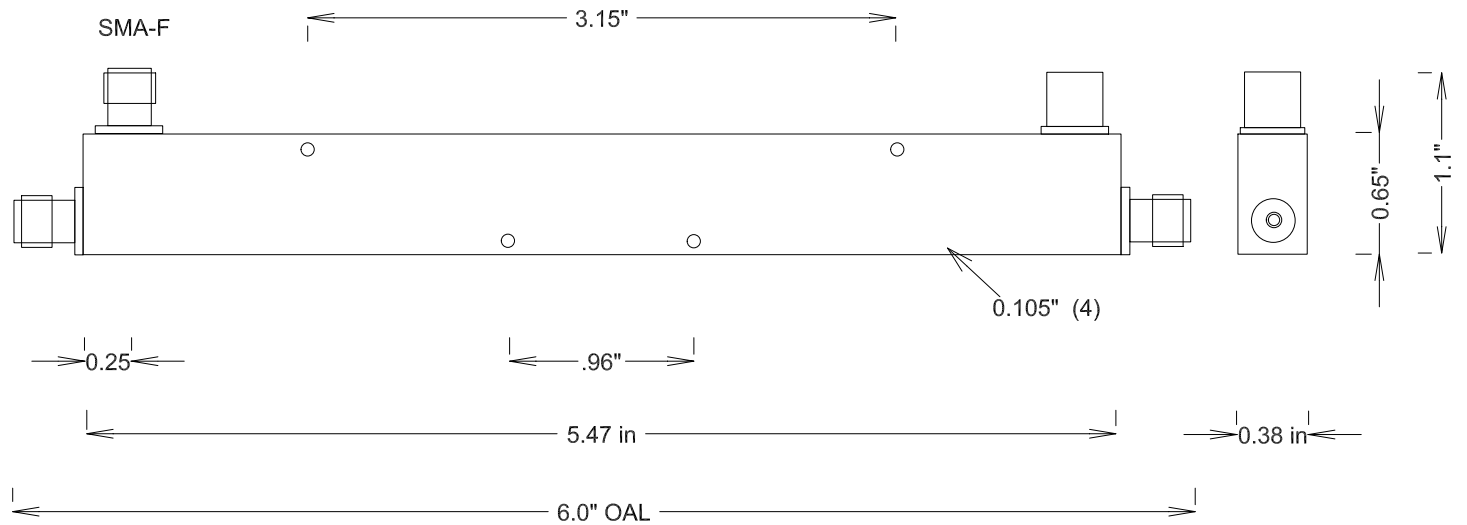

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

SMA DIRECTIONAL COUPLER .5-2GHZ

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	MC2024	
SCALE	SHEET		