

SMA DIRECTIONAL COUPLERS 1-4GHZ

MC2104

SPECIFICATIONS

ELECTRICAL:


FREQUENCY: 1-4 GHZ
 VSWR 1.25:1 MAX
 POWER CW: 50 WATTS
 POWER PEAK: 3KW
 DIRECTIVITY: 20 DB MIN
 TRUE LOSS: THRU: 6DB: 2.0DB
 TRUE LOSS: THRU: 10DB: 0.9DB
 TRUE LOSS: THRU: 20DB: 0.5DB
 FLATNESS: +/- 0.6DB
 IMPEDANCE: 50 OHMS
 ROHS COMPLIANT

MECHANICAL:

CONNECTORS: NICKEL PLATED BRASS
 CONNECTOR CONTACTS: AU PLATING

ENVIRONMENTAL:

TEMP: -55 C TO +125 C

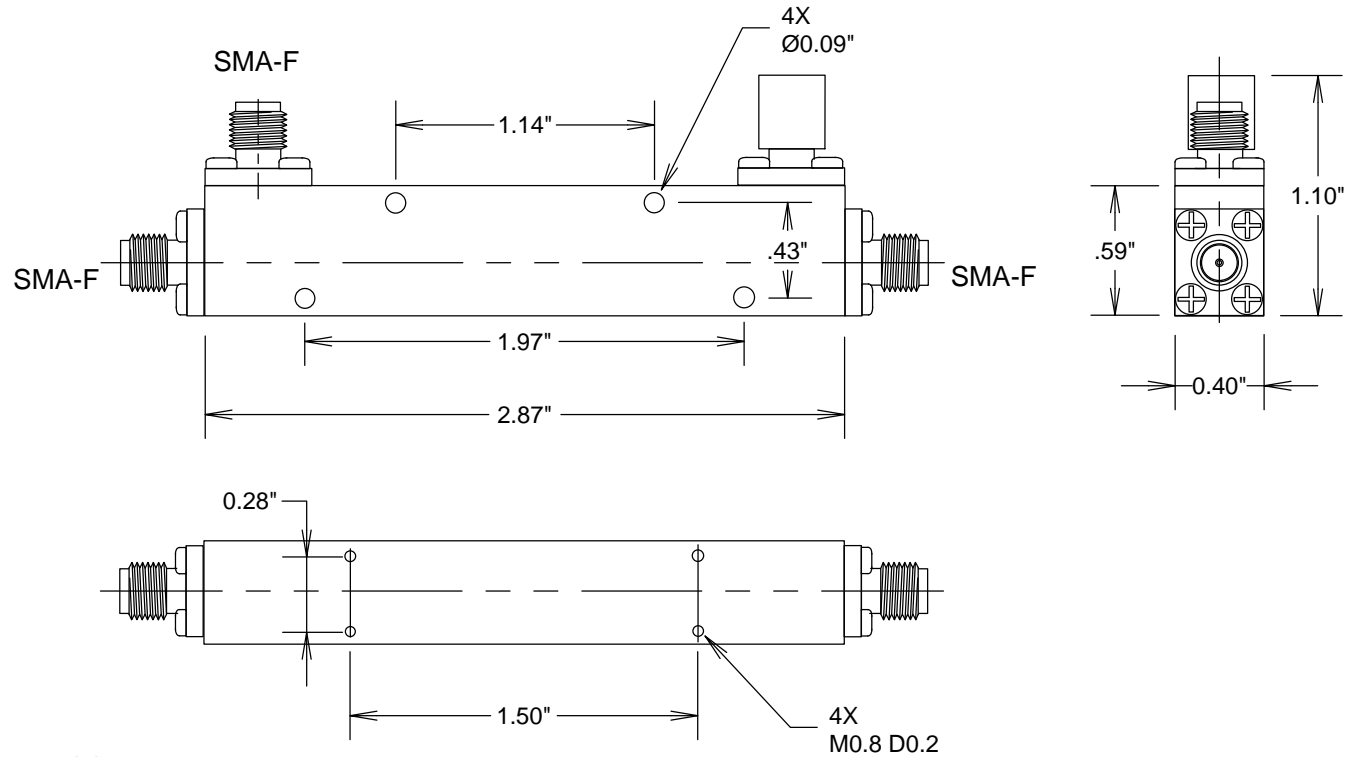

				FAIRVIEW MICROWAVE INC.	
				ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM	
				TITLE	
				SMA DIRECTIONAL COUPLERS 1-4GHZ	
SIZE	CAGE CODE	DWG NO		MC2104	REV
A	3FKR5				A
SCALE					SHEET