

# SPECIFICATIONS


## ELECTRICAL:

FREQUENCY: 0.5-1.0 GHZ  
 VSWR 1.10:1 MAX  
 POWER CW: 50 WATTS  
 POWER PEAK: 3KW  
 DIRECTIVITY: 25 DB MIN

TRUE LOSS: THRU: 10DB: 0.8DB  
 TRUE LOSS: THRU: 20DB: 0.2DB  
 TRUE LOSS: THRU: 30DB: 0.2DB  
 IMPEDANCE: 50 OHMS

## ENVIRONMENTAL:

TEMP: -55 C TO +125 C

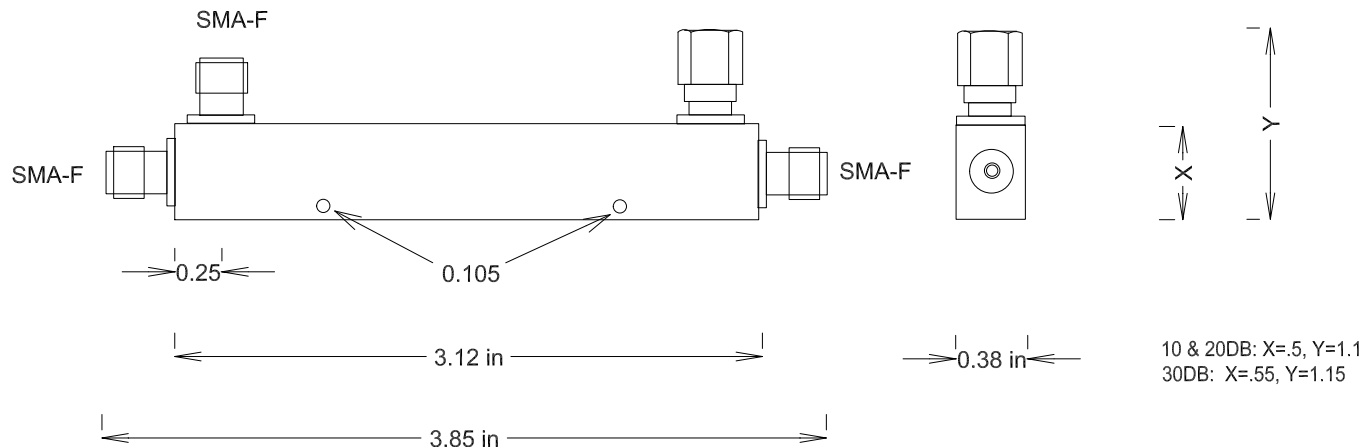

**FAIRVIEW MICROWAVE INC.**

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

**SMA DIRECTIONAL COUPLERS .5-1GHZ**

SIZE	CAGE CODE	DWG NO	REV
<b>A</b>	<b>3FKR5</b>	<b>MC3202</b>	
SCALE		SHEET	