


SPECIFICATIONS

ELECTRICAL:

FREQUENCY: 1-2 GHZ
 VSWR 1.10:1 MAX
 POWER CW: 50 WATTS
 POWER PEAK: 3KW
 DIRECTIVITY: 25 DB MIN
 TRUE LOSS: THRU: 10DB: 0.8DB
 TRUE LOSS: THRU: 20DB: 0.2DB
 TRUE LOSS: THRU: 30DB: 0.2DB
 IMPEDANCE: 50 OHMS

ENVIRONMENTAL:

TEMP: -55 C TO +125 C

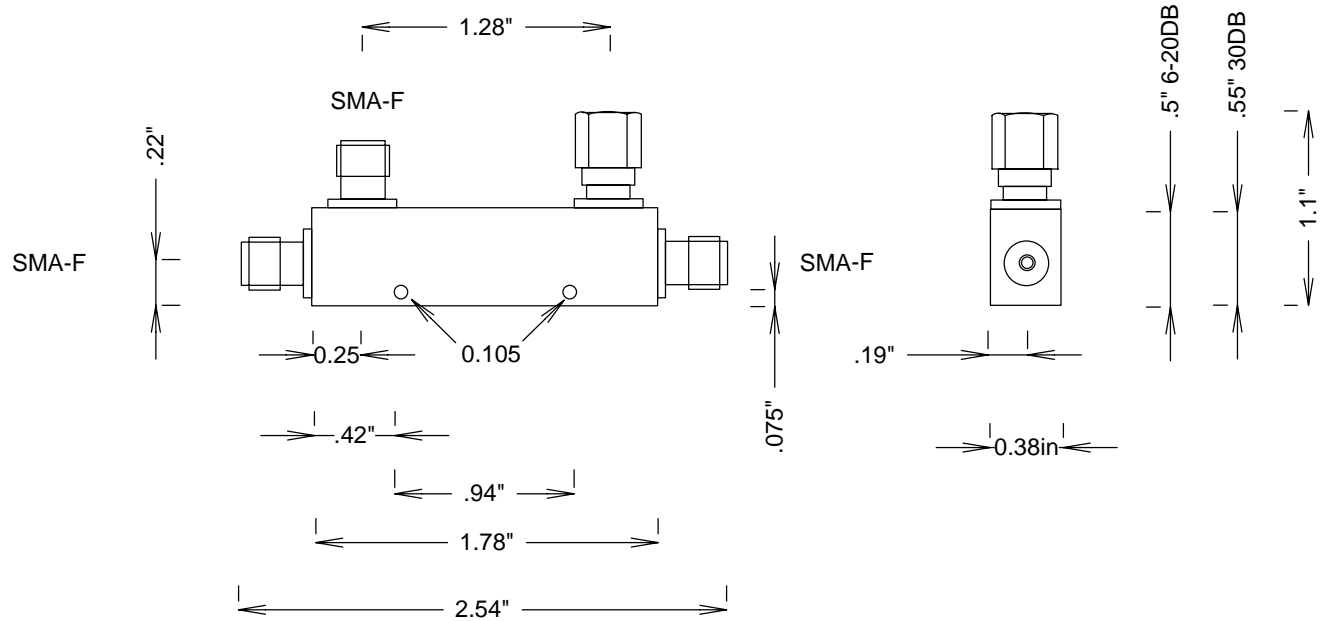

S. M. ELECTRONICS

FAIRVIEW, TX 75069 WWW.SMELECTRONICS.US

TITLE

SMA DIRECTIONAL COUPLER 1-2GHZ

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	MC3203	A
SCALE		SHEET	