

# POWER DIVIDER N 700-2700MHZ 3-WAY

MP0727N-3


## SPECIFICATIONS

### ELECTRICAL

FREQUENCY: 700-2700 MHZ  
PIM <150dBc (2 tones @ +43dBm)  
ISOLATION: 0 DB  
POWER: 500W AVG, 3KW PEAK  
IMPEDANCE: 50 OHMS  
VSWR: 1.25:1 MAX , ALL PORTS  
AMPLITUDE BALANCE: 0.15DB  
LOSS: 4.85 DB (4.8+.05)

### MECHANICAL

MATERIALS BODY: PASSIVATED ALUMINUM  
CONNECTORS: N-FEMALE, SILVER PLATING  
TEMP RANGE: -35 TO +75 DEG C  
MOUNTING BRACKET INCLUDED  
WEIGHT: 1.1LBS

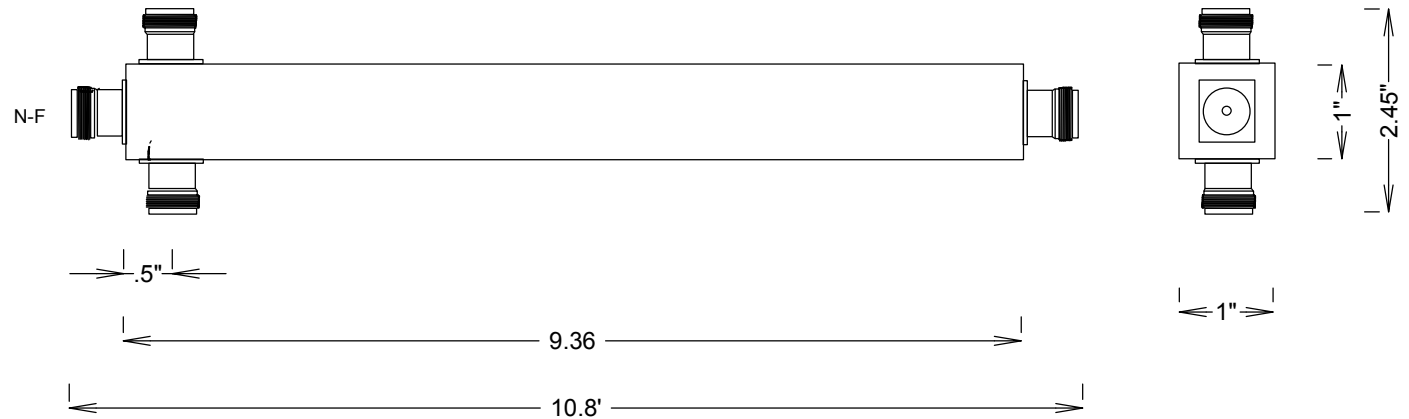

MOUNTING BRACKET INCLUDED

**FAIRVIEW MICROWAVE INC.**

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

**POWER DIVIDER N 700-2700MHZ 3-WAY**

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	MP0727N-3	
SCALE		SHEET	