

SMA POWER DIVIDER 2-WAY 698-2700 MHZ

MP8306-2

SPECIFICATIONS

ELECTRICAL:

FREQUENCY: 698-2700 MHZ
 VSWR 1.25:1
 POWER CW: 10 WATTS
 ISOLATION: 20 DB MIN
 INSERTION LOSS: 3.4 DB (3+.4)
 AMPLITUDE BALANCE: ± 0.3 DB MAX
 IMPEDANCE: 50 OHMS


MECHANICAL

CONNECTOR: Au PLATED NICKEL
 CONTACTS: Au PLATED PER MIL-G-45204
 HOUSING: PASSIVATED ALUMINUM

ENVIRONMENTAL:

TEMP: -30°C TO +60°C

ROHS COMPLIANT

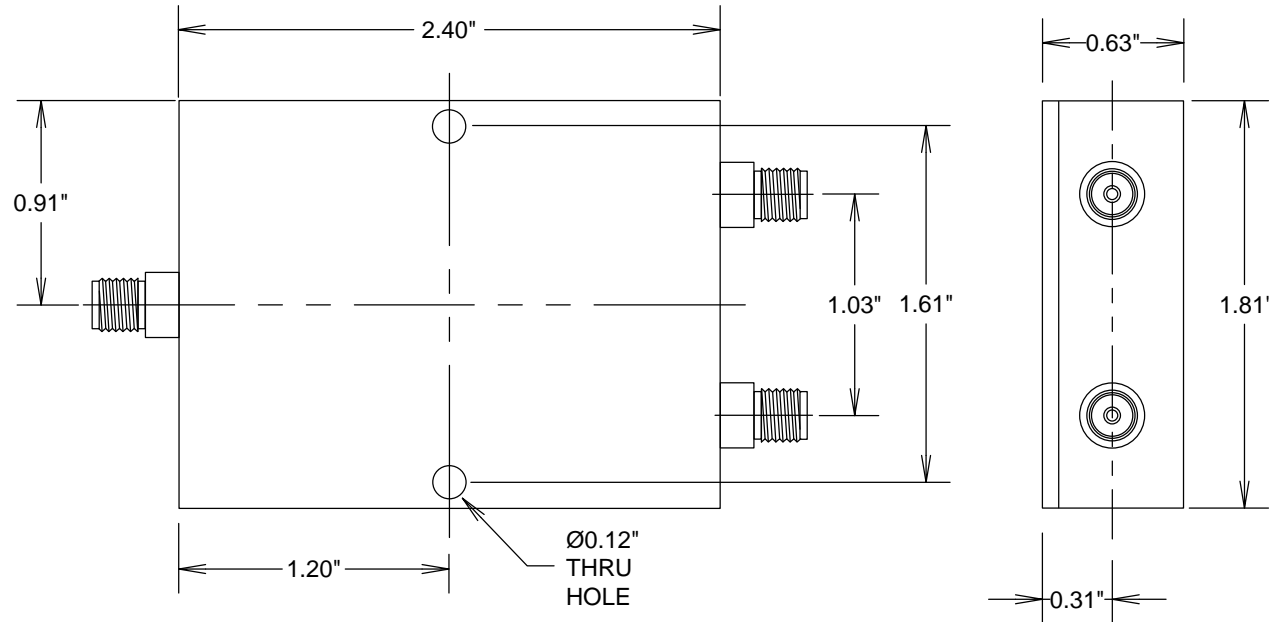

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

SMA POWER DIVIDER 2-WAY 698-2700 MHZ

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	MP8306-2	--

SCALE

SHEET