


UNIDIRECTIONAL

N-M
INPUT

N-F
OUTPUT

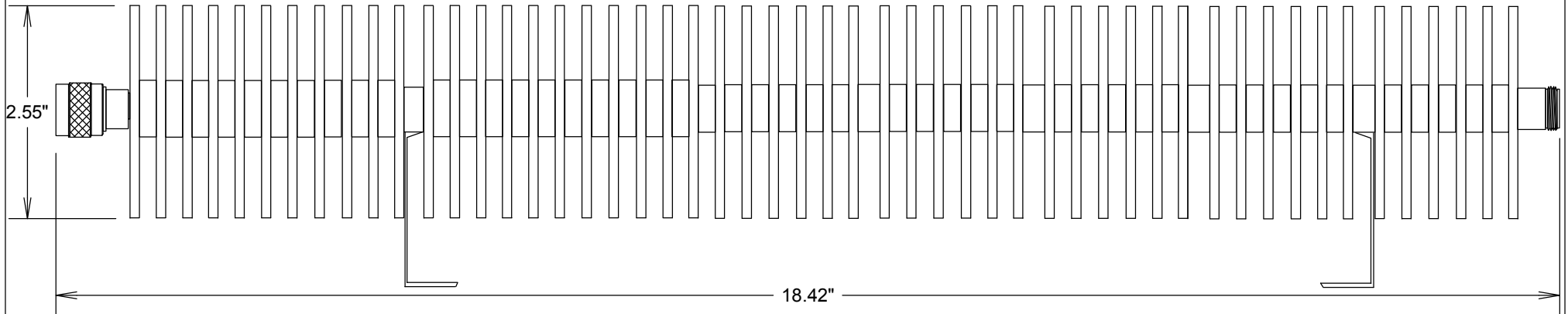

SPECIFICATIONS

ELECTRICAL:

FREQUENCY: 0-12.4 GHZ
 VSWR 1.3 @ 8 GHZ
 VSWR 1.6 @ 12.4 GHZ
 POWER (AVG) 350 WATTS @ 25° C
 POWER (PEAK) 5000 WATTS
 POWER DERATED LINEARLY TO 10 WATTS @ 100° C
 IMPEDANCE: 50 OHMS
 ATTENUATION ACCURACY:
 10DB +/- 2 DB @ 8 GHZ, 6 DB @ 12 GHZ
 20, 30 DB +/- 2.5 DB @ 8 GHZ, 5 DB @ 12 GHZ

UNIDIRECTIONAL

MECHANICAL:

MATERIAL CONNECTORS: STAINLESS STEEL
 FEMALE CONTACTS: Au PLATED BeCu
 MALE CONTACTS: STAINLESS STEEL
 INTERFACE: MIL-STD-348B
 TEMP: -25°C TO +100°C

ROHS COMPLIANT

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

ATTENUATORS N M/F 12.4 GHZ 350 W

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SA12N350-XX	--
SCALE		SHEET	