

ATTENUATORS SMA M/F 18GHZ 100W

SA18S100W-XX

SPECIFICATIONS

ELECTRICAL:

FREQUENCY: 0-18 GHZ

VSWR 1.20 MAX TO 8 GHZ

1.25 MAX TO 12 GHZ

1.35 MAX TO 18 GHZ

POWER (AVG) 100 WATTS @ 25° C

POWER (PEAK) 1000 WATTS

IMPEDANCE: 50 OHMS

ATTENUATION ACCURACY: 10DB +/- .75db;

20db +/- 1.0db; 30, 40db +/- 1.2 db

UNIDIRECTIONAL

MECHANICAL:

MATERIAL CONNECTORS: PASSIVATED STAINLESS STEEL


MATERIAL RING & CONTACTS: BeCu

CENTER CONTACT: GOLD PLATED PER MIL-G-45204

INTERFACE: MIL-STD-348B

INSULATOR: TEFLON

TEMP: -55°C TO +125°C

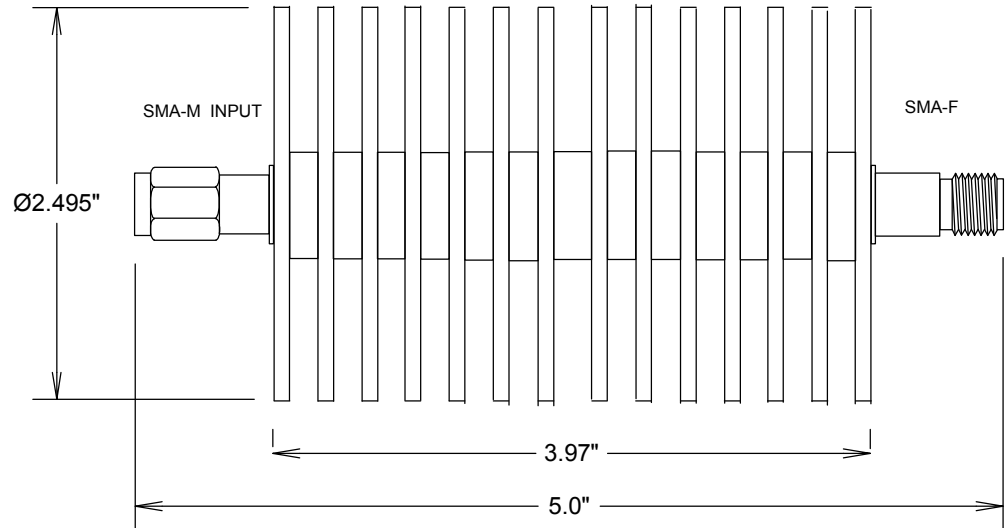

UNIDIRECTIONAL; MALE IF NOT SPECIFIED

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

ATTENUATORS SMA M/F 18GHZ 100W

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SA18S100W-XX	--
SCALE	SHEET		