

BNC ATTENUATORS 75 OHM 2 GHZ

SA2B75-XX

SPECIFICATIONS


ELECTRICAL

FREQUENCY: 0-2 GHZ
IMPEDANCE: 75 OHMS
VSWR: 1.3:1 MAX
POWER: 2 WATTS CW @ 25 DEG C
ACCURACY: +/- 0.8DB

MECHANICAL

MATERIAL BODY : NICKLE PLATED BRASS
CONTACT PLATING: Au

ROHS COMPLIANT

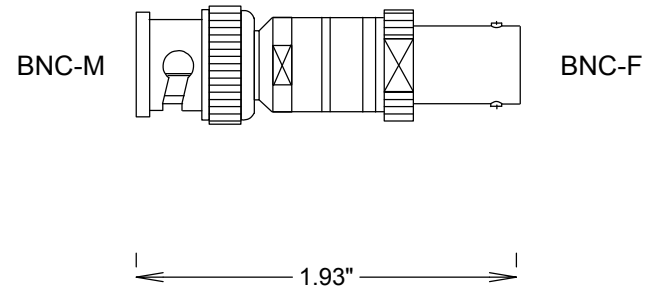

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

BNC ATTENUATORS 75 OHM 2 GHZ

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SA2B75-XX	--

SCALE

SHEET