

ATTENUATORS SMA M/F 3GHZ

SA3011-XX

SPECIFICATIONS

ELECTRICAL:


FREQUENCY: 0-3 GHZ
 VSWR 1.15 MAX
 POWER (AVG) 2 WATTS
 POWER (PEAK) 250 WATTS
 IMPEDANCE: 50 OHMS
 ATTENUATION ACCURACY:
 GREATER OF +/- .3 DB OR 3%

MECHANICAL:

MATERIAL BODY: NICKEL PLATED BRASS
 MATERIAL RING & CONTACTS: BeCu
 CENTER CONTACT: Au PLATED 30 μin

ENVIRONMENTAL:

TEMP: -55 C TO +125 C
 ROHS COMPLIANCE

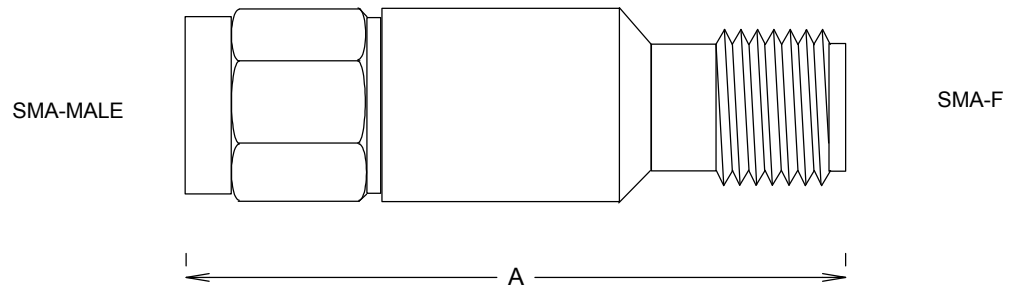

PLEASE REFERENCE TABLE BELOW

Db Value	Length
1,2,3,6,10,15	.962"
20,30	1.05"

				FAIRVIEW MICROWAVE INC.			
				ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM			
				TITLE			
				ATTENUATORS SMA M/F 3GHZ			
SIZE	CAGE CODE	DWG NO		REV			
A	3FKR5	SA3011-XX		A			
SCALE				SHEET			