

STEP ATTEN. SMA-F'S 3GHZ 10DB 1DB STEPS

SA3510

SPECIFICATIONS


ELECTRICAL:

FREQUENCY: 0-3 GHZ
 ATTENUATION RANGE: 0-10 DB
 ATTENUATION STEPS: 1DB
 VSWR @ 1GHZ: 1.25:1 MAX
 VSWR @ 2GHZ: 1.35:1 MAX
 VSWR @ 3GHZ: 1.5:1 MAX
 POWER (AVG) 2 WATTS @ 25 DEG C
 POWER (PEAK) 1KW
 IMPEDANCE: 50 OHMS

ATTENUATION ACCURACY:
 GREATER OF +/- .25DB
 GREATER OF +/- .35DB
 GREATER OF +/- .50DB

INSERTION LOSS
 .25DB MAX @ 1GHZ
 .50DB MAX @ 2GHZ
 .75DB MAX @ 3GHZ

ENVIRONMENTAL:
 TEMP: -55° C TO +100° C

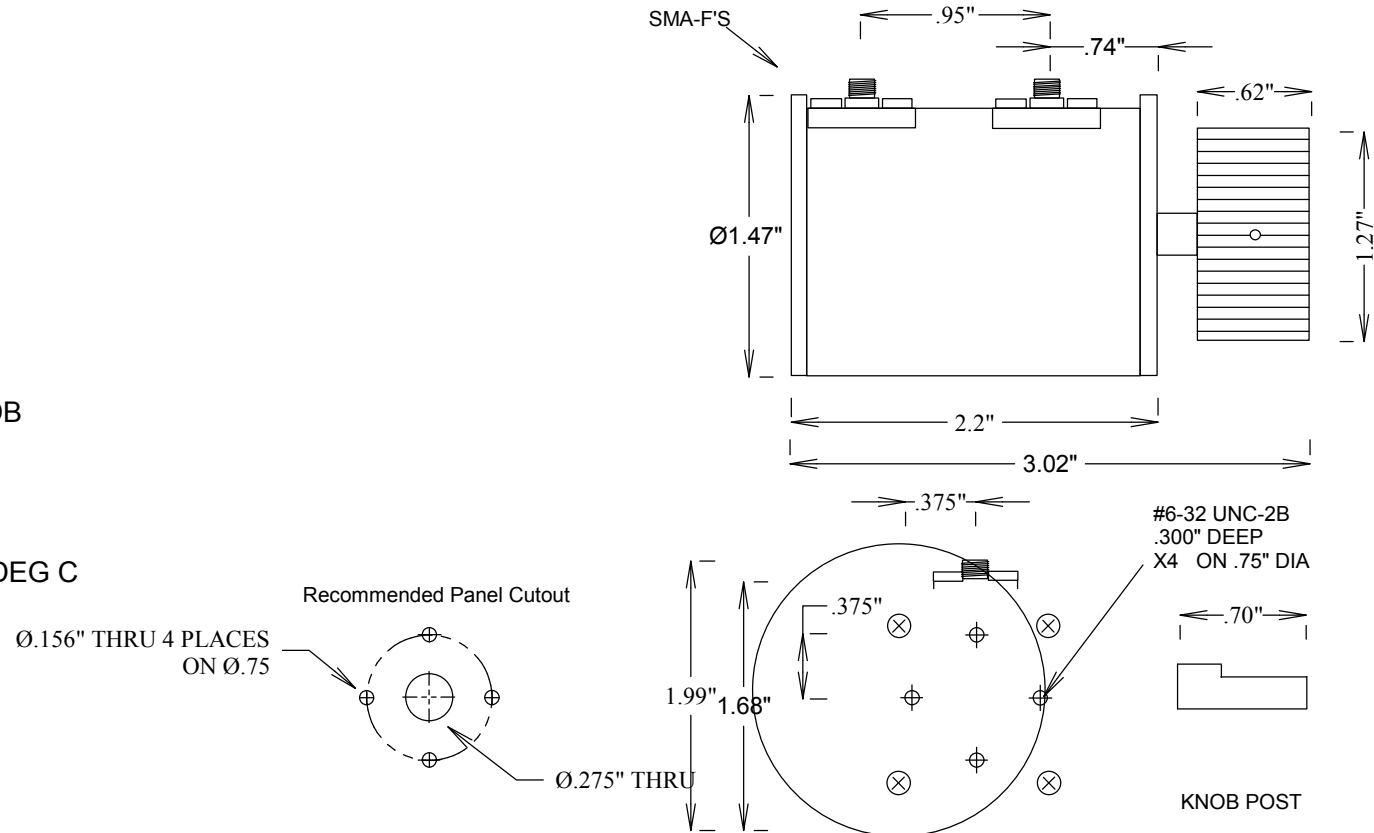

				FAIRVIEW MICROWAVE INC.	
				ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM	
				TITLE	
				STEP ATTEN. SMA-F'S 3GHZ 10DB 1DB STEPS	
SIZE	CAGE CODE	DWG NO	SA3510		
A	3FKR5				
SCALE			SHEET		
			REV A		