

# BNC ATTENUATORS 75 OHM 3GHZ

SA3B75-XX

## SPECIFICATIONS


### ELECTRICAL

FREQUENCY: 0-3 GHZ  
IMPEDANCE: 75 OHMS  
VSWR: 1.3:1 MAX  
POWER: 2 WATTS CW @ 25 DEG C  
ACCURACY: +/- 0.8DB

### MECHANICAL

MATERIAL BODY : NICKLE PLATED BRASS  
CONTACT MATERIAL FEMALE: BeCu  
CONTACT MATERIAL MALE: BRASS  
CONTACT PLATING: Au MIL-G-45204  
INSULATOR: TEFLON  
INTERFACE: MIL-STD-348B

ROHS COMPLIANT

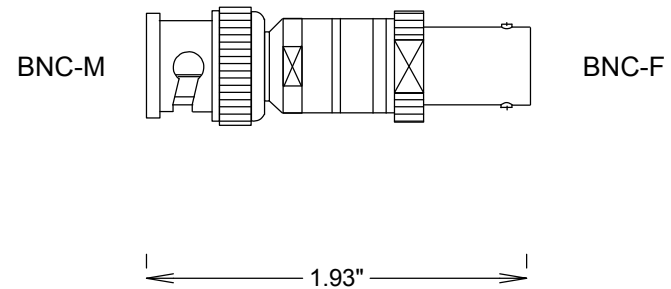

				<b>FAIRVIEW MICROWAVE INC.</b>			
				ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM			
				TITLE			
				BNC ATTENUATORS 75 OHM 3GHZ			
SIZE		CAGE CODE		DWG NO		REV	
A		3FKR5		SA3B75-XX		--	
SCALE				SHEET			