

ATTENUATORS N M/F 3GHZ 10W

SA3N10W-XX

SPECIFICATIONS

ELECTRICAL:


FREQUENCY: 0-3 GHZ
VSWR 1.20 MAX
POWER (AVG) 10 WATTS @ 25 DEG C
POWER (PEAK) 1000 WATTS
IMPEDANCE: 50 OHMS
ATTENUATION ACCURACY:
1-9 DB +/- .4DB
10 DB +/- .5DB
20, 30 DB +/- .6DB
40 DB +/- 1DB
POWER DERATED LINEARLY TO 1W
@ 125 DEG C

MECHANICAL:

MATERIAL CONNECTORS: NICKEL PLATED BRASS
MATERIAL CONTACTS MALE: Au PLATED BRASS
MATERIAL CONTACTS FEMALE: Au PLATED BeCu

TEMP: -55 C TO +125 C

ROHS COMPLIANT

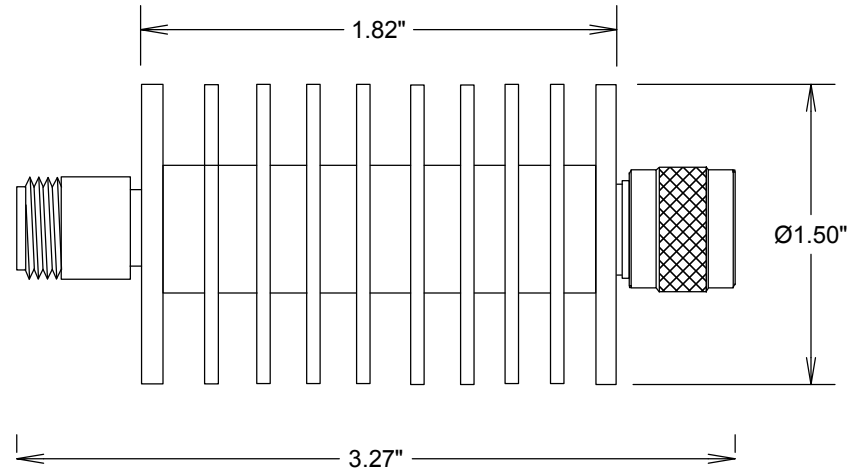

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

ATTENUATORS N M/F 3GHZ 10W

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SA3N10W-XX	--

SCALE

SHEET