

ATTENUATORS N 25 WATTS 4GHZ

SA4N25-XX

SPECIFICATIONS

ELECTRICAL:


FREQUENCY: 0-4 GHZ
 VSWR 1.2:1 MAX
 POWER (AVG) 25 WATTS @ 25 °C
 DERATES TO 2.5WATTS @ 125 °C
 POWER (PEAK) 5KW (5µs PULSE, .5% DUTY CYCLE)
 ATTENUATION ACCURACY:
 1-30DB: +/- 0.6DB; 40 DB +/- 1DB
 IMPEDANCE: 50 OHMS

CONNECTORS:

MATERIAL BODY: PASS STAINLESS STEEL
 MATERIAL CONTACTS: BeCu
 CONTACT PLATING: Au, MIL-G-45205
 INTERFACE: MIL-STD-348A

ENVIRONMENTAL:

TEMP: -55 C TO +125 C
 REQUIRES MOUNTING ON FLAT CONDUCTIVE PLATE
 ROHS COMPLIANT

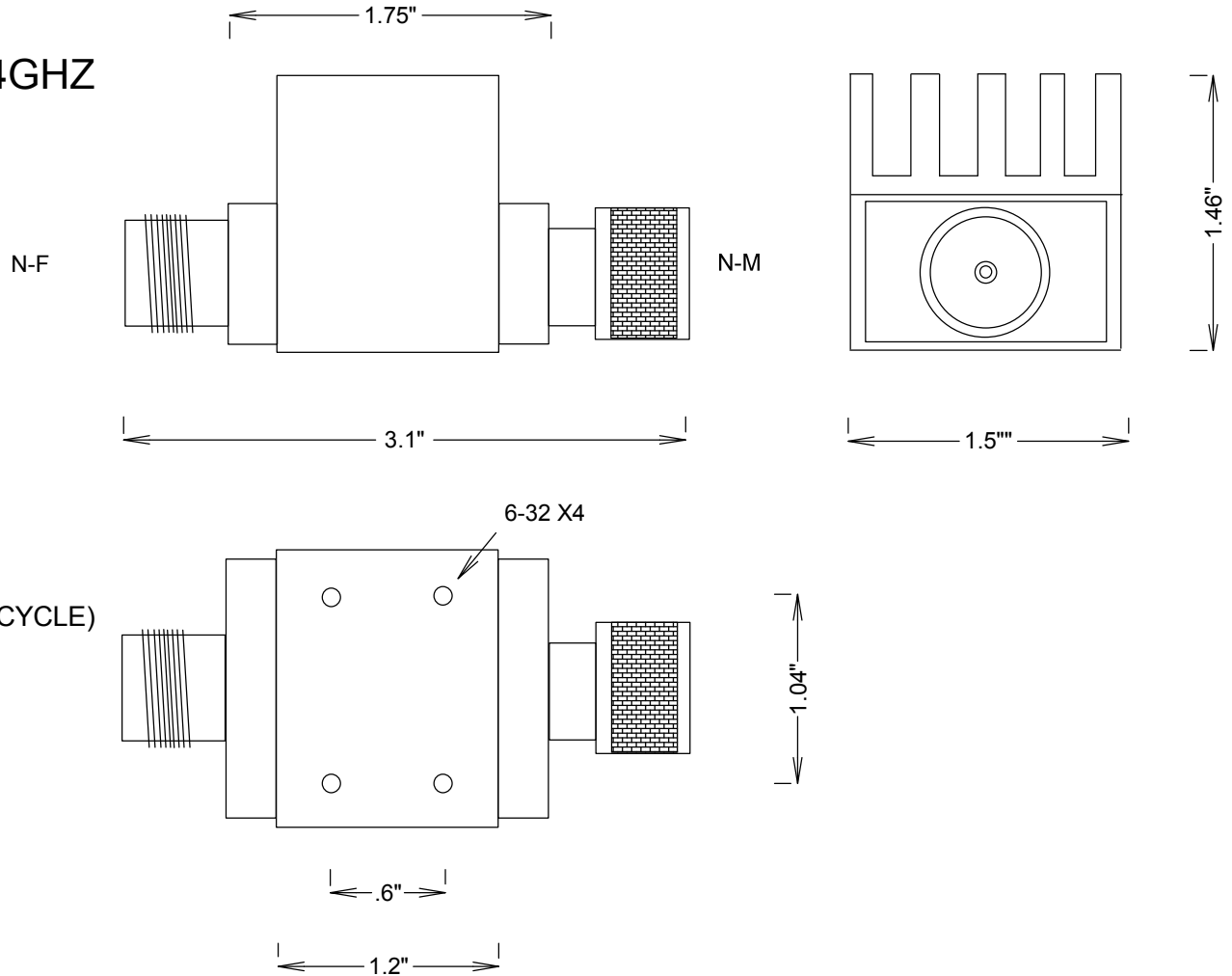

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

ATTENUATORS N 25 WATTS 4GHZ

SIZE	CAGE CODE	DWG NO.	REV
A	3FKR5	SA4N25-XX	A
SCALE		SHEET	