

# ATTENUATORS N M/F 4GHZ 50W

SA4N50W-XX

## SPECIFICATIONS


### ELECTRICAL:

FREQUENCY: 0-4 GHZ  
 VSWR 1.20 MAX  
 POWER (AVG) 50 WATTS @ 25 DEG C  
 POWER (PEAK) 1000 WATTS  
 IMPEDANCE: 50 OHMS  
 ATTENUATION ACCURACY:  
 3-20DB +/- .4DB  
 30-40DB +/- .6BD  
 BIDIRECTIONAL EXCEPT FOR 50 DB VALUES

### MECHANICAL:

MATERIAL CONNECTORS: PASSIVATED STAINLESS STEEL  
 MATERIAL RING & CONTACTS: BeCu  
 CENTER CONTACT: GOLD PLATED PER MIL-G-45204  
 INTERFACE: MIL-STD-348B  
 INSULATOR: TEFLON  
 TEMP: -55 C TO +125 C

ROHS COMPLIANT

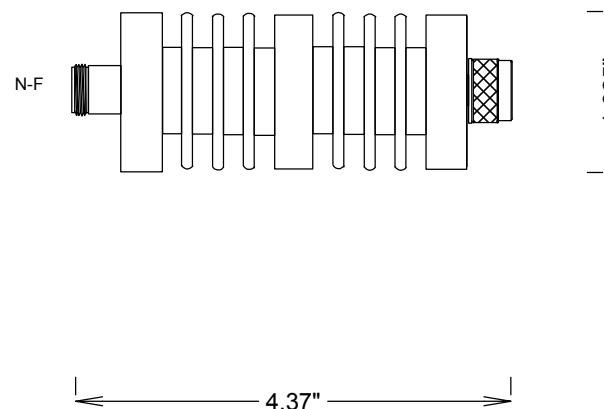

				<b>FAIRVIEW MICROWAVE INC.</b>	
				ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM	
				TITLE	
				<b>ATTENUATORS N M/F 4GHZ 50W</b>	
SIZE	CAGE CODE	DWG NO			
<b>A</b>	3FKR5	<b>SA4N50W-XX</b>	REV		
			SCALE	SHEET	