

ATTENUATORS SMA 25 WATTS 4GHZ

SA4S25-XX

SPECIFICATIONS

ELECTRICAL:

FREQUENCY: 0-4 GHZ
 VSWR 1.2:1 MAX
 POWER (AVG) 25 WATTS @ 25 °C
 DERATES TO 2.5WATTS @ 125 °C
 ATTENUATION ACCURACY:
 1-30DB: +/- 0.6DB; 40 DB +/- 1DB
 IMPEDANCE: 50 OHMS

CONNECTORS:



MATERIAL BODY: PASS STAINLESS STEEL
 MATERIAL CONTACTS: BeCu
 CONTACT PLATING: Au, MIL-G-45205
 INTERFACE: MIL-STD-348A

ENVIRONMENTAL:

TEMP: -55 C TO +125 C

REQUIRES MOUNTING ON FLAT
 CONDUCTIVE PLATE

ROHS COMPLIANT

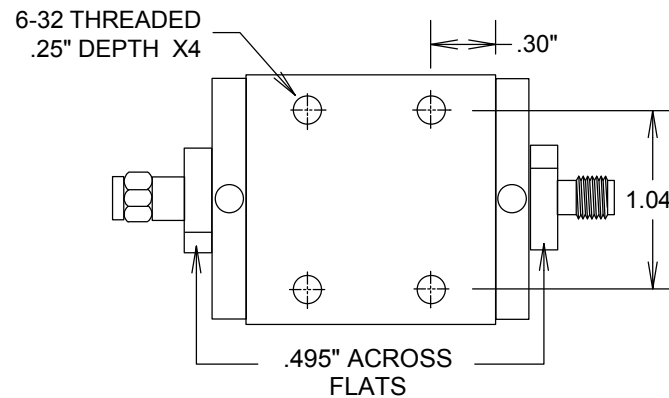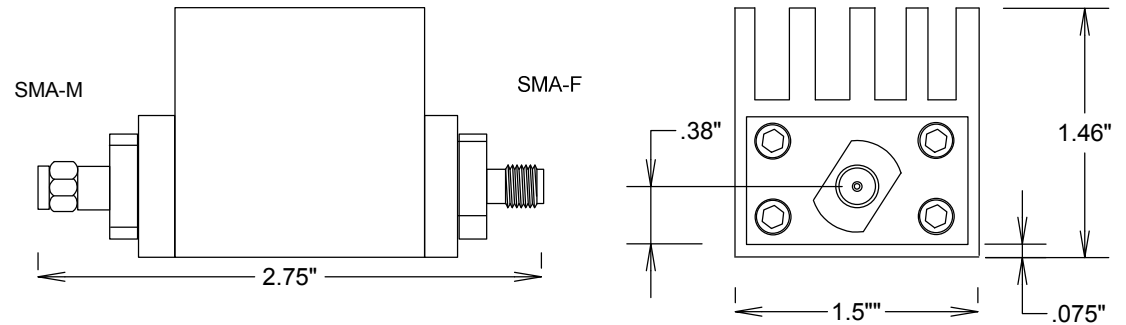

				FAIRVIEW MICROWAVE INC.	
				ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM	
				TITLE	
				ATTENUATORS SMA 25 WATTS 4GHZ	
SIZE	CAGE CODE	DWG NO	REV		
A	3FKR5	SA4S25-XX	A		
SCALE			SHEET		