

# ATTENUATORS SMA M/F 4 GHZ 25 W

SA4S252-XX

## SPECIFICATIONS


**ELECTRICAL:**

FREQUENCY: 0-4 GHZ  
 VSWR 1.25 MAX @ 4 GHZ  
 POWER (AVG) 25 WATTS @ 25° C  
 POWER (PEAK) 1000 WATTS  
 IMPEDANCE: 50 OHMS

ATTENUATION ACCURACY				
1-9 dB	10 dB	20 dB	30 dB	40 dB
±0.5	±0.6	±0.75	±0.75	±1.0

**MECHANICAL:**

MATERIAL CONNECTORS: NICKEL PLATED BRASS  
 MATERIAL RING & CONTACTS: BeCu  
 CENTER CONTACT: GOLD PLATED PER MIL-G-45204  
 INTERFACE: MIL-STD-348B  
 INSULATOR: TEFLON  
 TEMP: -55°C TO +125°C

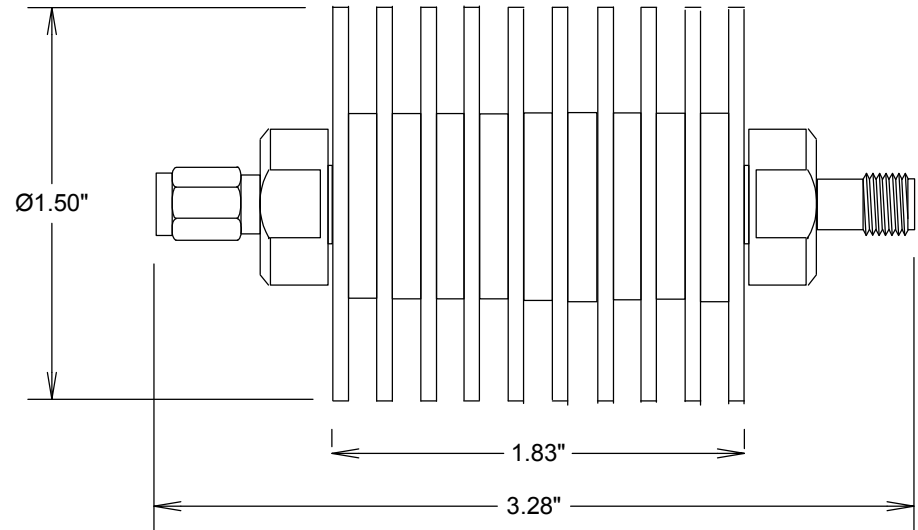

				<b>FAIRVIEW MICROWAVE INC.</b>	
				ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM	
				TITLE	
				<b>ATTENUATORS SMA M/F 4 GHZ 25 W</b>	
		SIZE	CAGE CODE	DWG NO	REV
		<b>A</b>	3FKR5	SA4S252-XX	--
				SCALE	SHEET