

ATTENUATORS SMA M/F 6 GHZ

SA6H-XX

SPECIFICATIONS

ELECTRICAL:

FREQUENCY: 0-6 GHZ
 VSWR 1.20 MAX TO 6 GHZ
 POWER (AVG) 2 WATTS @ 25 DEG C


IMPEDANCE: 50 OHMS
 ATTENUATION ACCURACY:
 +/- .3 0-6 DB
 +/- 0.5 7-20 DB
 +/- 0.75 21-30 DB

MECHANICAL:

MATERIAL BODY: PASSIVATED STAINLESS STEEL
 MATERIAL RING & CONTACTS: BeCu
 CENTER CONTACT: GOLD PLATED PER MIL-G-45204
 RECOMMENDED TORQUE: 7-9 IN-LBS

ENVIRONMENTAL:

TEMP: -55 C TO +125 C
 ROHS COMPLIANT

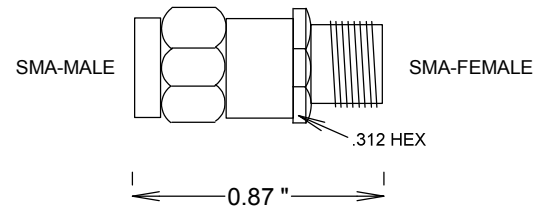

				FAIRVIEW MICROWAVE INC.	
				ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM	
				TITLE	
				ATTENUATORS SMA M/F 6 GHZ	
SIZE	CAGE CODE	DWG NO			REV
A	3FKR5	SA6H-XX			--
SCALE					SHEET