

BNC INNER DC BLOCK

SD3123


SPECIFICATIONS

ELECTRICAL

FREQUENCY: 0.01-3 GHZ
IMPEDANCE: 50 OHMS
VSWR: 1.25:1 MAX
INSERTION LOSS: 0.2DB MAX @2GHZ;
0.35DB MAX@3GHZ
200 VOLTS

MECHANICAL

MATERIALS BODY: NICKEL PLATED BRASS

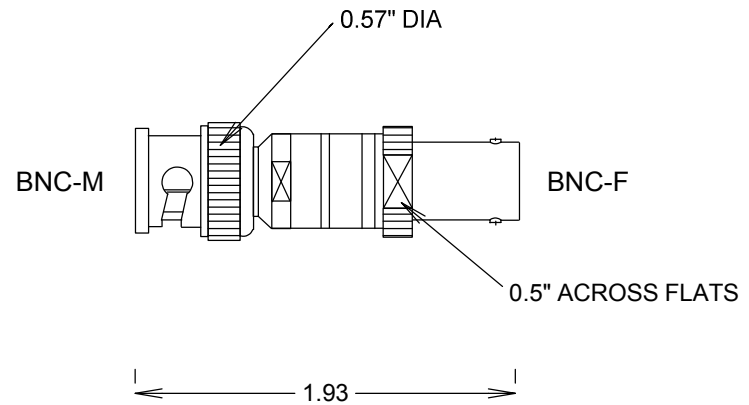

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

BNC INNER DC BLOCK

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SD3123	
SCALE	SHEET		