

ISOLATOR 26.5-40 GHZ

SFI2640

SPECIFICATIONS

ELECTRICAL

FREQUENCY: 26.5-40 GHZ

IMPEDANCE: 50 OHMS

VSWR: 1.45:1 TYP; 1.50:1 MAX

LOSS: 0.80 DB TYP; 1.00 DB MAX

POWER: AVG(P1 TO P2) :5W

REFLECTIVE POWER(TERM): 2W

PEAK: 30 W

ISOLATION: 15 DB TYP; 14 DB MIN


MECHANICAL

MATERIAL CONNECTORS: PASSIVATED STAINLESS STEEL

MATERIAL CONTACTS: BeCu

CONTACT PLATING: Au PER MIL-G-45204

-20°C TO +65°C

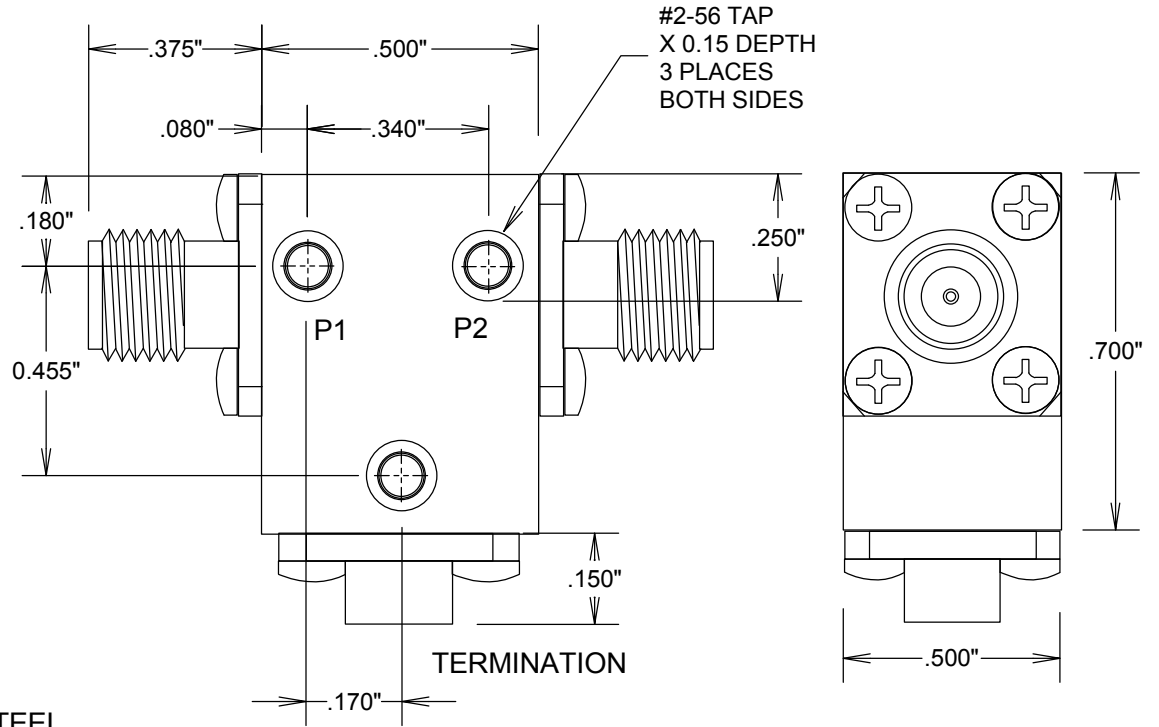

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

ISOLATOR 26.5-40 GHZ

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SFI2640	--
SCALE		SHEET	