

# ISOLATOR 4-8 GHZ

SFI4080

## SPECIFICATIONS


### ELECTRICAL

FREQUENCY: 4-8 GHZ  
IMPEDANCE: 50 OHMS  
VSWR: 1.25:1 MAX  
LOSS: 0.5DB MAX  
POWER<sub>in</sub>: 10W MAX  
ISOLATION: 19DB MIN

### MECHANICAL

HOUSING: ALUMINUM  
CONNECTORS: SMA-F, Ni PLATED BRASS

-40 to +70 DEG C

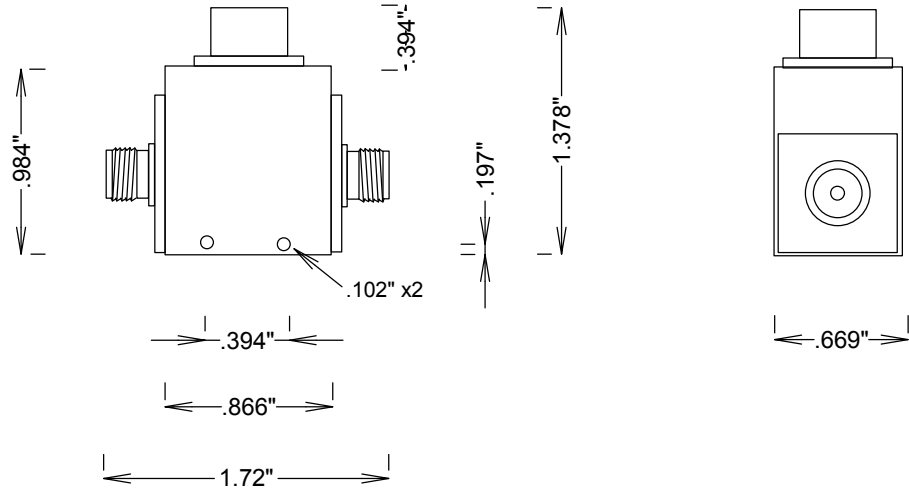

**FAIRVIEW MICROWAVE INC.**

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

**ISOLATOR 4-8 GHZ**

SIZE	CAGE CODE	DWG NO	REV
<b>A</b>	<b>3FKR5</b>	<b>SFI4080</b>	
SCALE	SHEET		