

SPECIFICATIONS


CABLE ASSEMBLY:
 FREQUENCY: 0-40GHZ
 VSWR 1.35:1 MAX @ 40GHZ

CABLE:
 086 HAVERHILL .086 SOLID AI OR EQ
 086B MICROCOAX UT-85-FORM (TIN DIPPED)
 DIAMETER: .086"
 LOSS: 1.3 DB/FT 20GHZ (EXC CONN'S)
 LOSS: 1.8 DB/FT 40GHZ (EXC CONN'S)

CONNECTORS:
 2.92mm MALE
 BODY: PASS. STAINLESS STEEL
 PIN: Au PLATED MIL-G-45204
 8-10 in-lbs TORQUE

TEMPERATURE: -55 - +100°C

ROHS COMPLIANT

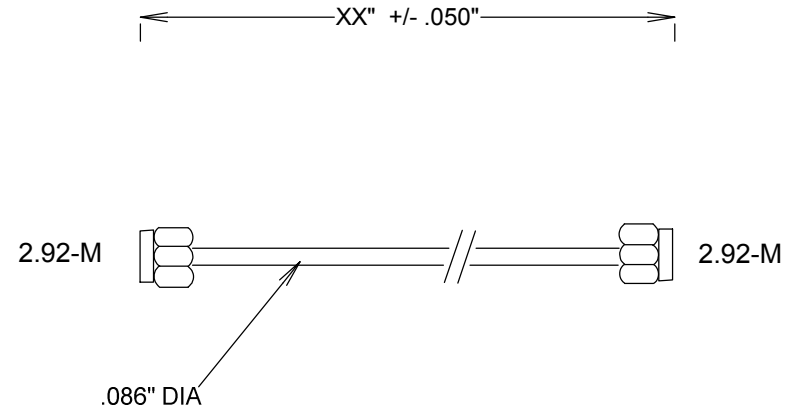

THESE CABLES CAN BE FORMED BY HAND;
 THEY RETAIN THEIR SHAPE UPON FORMING

				FAIRVIEW MICROWAVE INC.			
				ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM			
				TITLE			
				2.92 FORMABLE SEMIRIGID CABLES			
SIZE		CAGE CODE		DWG NO		REV	
A		3FKR5		SKPS086, SKPS086B		--	
SCALE				SHEET			