


10-32 / BNC ADAPTERS 2GHZ

SM2407, SM2409

SPECIFICATIONS

ELECTRICAL
 FREQUENCY: 0-2 GHZ
 IMPEDANCE: 50 OHMS
 VSWR: 1.2:1 MAX @ 2GHZ

MECHANICAL
 MATERIAL BODY: NICKEL PLATED BRASS
 CONTACTS: BeCu
 CONTACT PLATING: Au PER MIL-G-45204
 INTERFACE: BNC: MIL-STD-348A
 TEMPERATURE: -65° +125°C

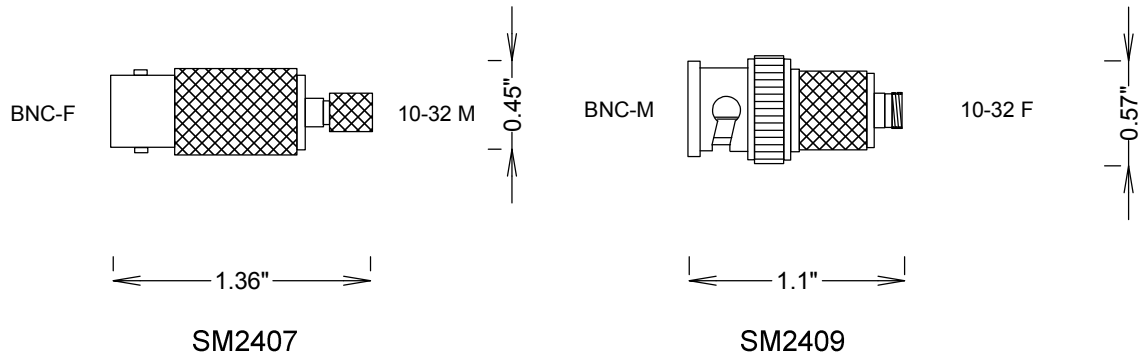

				FAIRVIEW MICROWAVE INC.	
				ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM	
				TITLE	
				10-32 / BNC ADAPTERS 2GHZ	
SIZE		CAGE CODE	DWG NO	REV	
A		3FKR5	SM2407, SM2409	--	
SCALE			SHEET		