

ADAPTER SMP M/M 40GHZ

SM2605


SPECIFICATIONS

ELECTRICAL:

FREQUENCY: 0-40 GHZ
 IMPEDANCE: 50 OHMS
 VSWR: 1.3:1 MAX

MECHANICAL:

MATERIAL SMP BODY: BeCu
 MATERIAL SMA BODY: PASS S STEEL
 CENTER CONTACTS: BeCu
 CONTACT PLATING: Au PER MIL-G-45204
 INSULATOR: PTFE
 INTERFACE: SMP DESC 94007
 OP. TEMP RANGE: -55° to +125°C
 ROHS COMPLIANT
 SMP FORCE TO ENGAGE: 15.0 LBS MAX FD,
 2.0 LBS S BORE
 SMP FORCE TO DISENGAGE: 5.0 LBS MIN FD,
 0.5 LBS S BORE

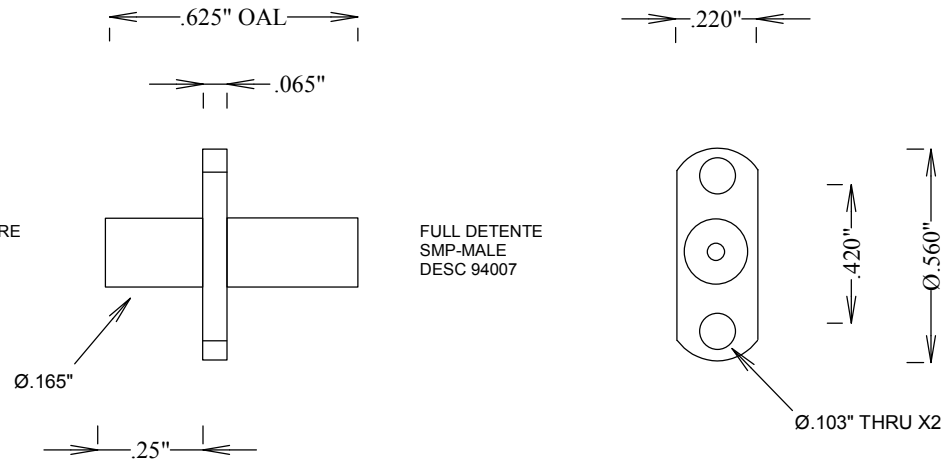

				FAIRVIEW MICROWAVE INC.			
				ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM			
				TITLE			
				ADAPTER SMP M/M 40GHZ			
SIZE	CAGE CODE	DWG NO				REV	
A	3FKR5	SM2605				A	
SCALE						SHEET	