

# 2.4mm - 3.5mm ADAPTERS 33GHZ

SM3062, SM3067, SM3072, SM3077





## SPECIFICATIONS

**ELECTRICAL**  
 50 OHMS  
 VSWR 1.15:1 MAX @ 33 GHZ

**MECHANICAL**  
 500 CYCLES MIN  
 4.0 INCH-OUNCES MIN CONTACT TORQUE  
 8-10 LBS COUPLING NUT MATING TORQUE  
 INTERFACE: MIL-STD-348A

**ENVIRONMENTAL**  
 -55 TO +135° C

**MATERIALS**  
 BODY: PASS. S STEEL  
 CONTACT: BeCu  
 CONTACT PLATING: Au, MIL-G-45204  
 DIELECTRIC: KEL-F PER MIL-P-46036

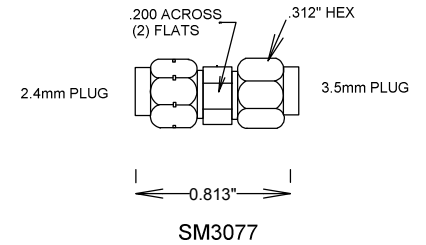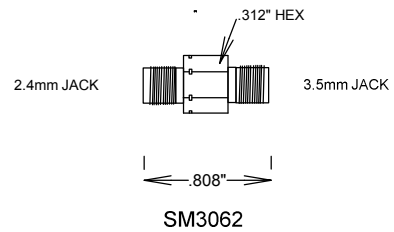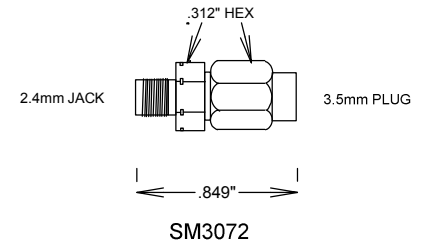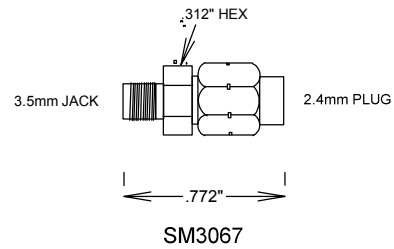

				<b>FAIRVIEW MICROWAVE INC.</b>			
				ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM			
				TITLE			
				<b>2.4mm - 3.5mm ADAPTERS 33GHZ</b>			
SIZE		CAGE CODE		DWG NO		REV	
<b>A</b>		3FKR5		SM3062, SM3067, SM3072, SM3077		--	
SCALE				SHEET			