

BMA (OSP)/JACK TO SMA/JACK BULKHEAD

SM3296

SPECIFICATIONS

ELECTRICAL


FREQUENCY: 0-18 GHZ
 IMPEDANCE: 50 OHMS
 VSWR 1.15:1 MAX
 (BMA GOOD TO 22GHZ;
 SMA MAY MODE ABOUT 20.5GHZ)

MECHANICAL

DURABILITY: 500 CYCLES MIN.
 TEMPERATURE RANGE: -65 TO +125 DEG C

MATERIALS

BODY PASS STAINLESS STEEL
 CONTACTS BeCu, Au PLATING
 INTERFACE: MIL-STD-348A

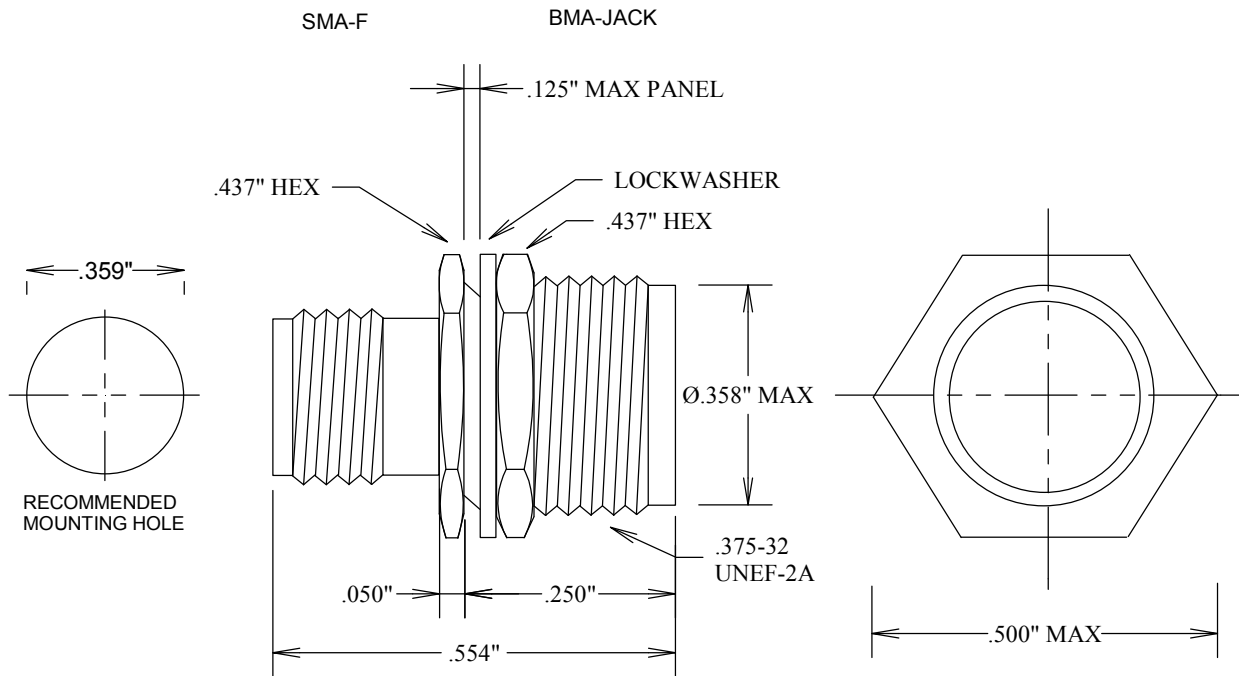

				FAIRVIEW MICROWAVE INC.			
				ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM			
				TITLE			
				BMA (OSP)/JACK TO SMA/JACK BULKHEAD			
SIZE		CAGE CODE		DWG NO		REV	
A		3FKR5		SM3296		A	
SCALE				SHEET			