

3.5-3.5mm M/F FLANGE ADAPTER

SM3321

SPECIFICATIONS

ELECTRICAL


FREQUENCY: 0-34 GHZ
 IMPEDANCE: 50 OHMS
 VSWR: 1.25:1 MAX

MECHANICAL

500 CYCLES MIN
 4.0 IN-OUNCES MIN CONTACT TORQUE
 8-10 IN-LBS COUPLING NUT MATING TORQUE
 DURABILITY: 500 CYCLES MIN.
 TEMPERATURE RANGE: -55 TO +100 DEG C

MATERIALS

BODY PASS STAINLESS STEEL
 CONTACTS BeCu
 CONTACT PLATING: Au MIL-G-45204
 ROHS COMPLIANT

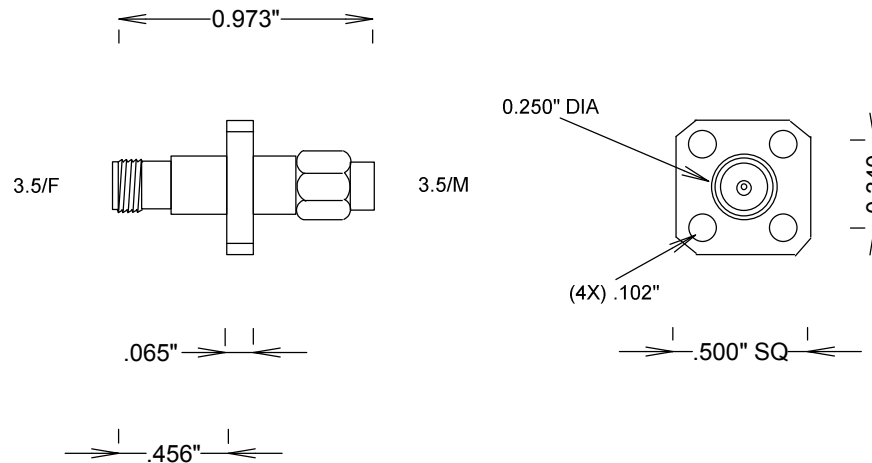

				FAIRVIEW MICROWAVE INC.	
				ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM	
				TITLE	
				3.5-3.5mm M/F FLANGE ADAPTER	
SIZE		CAGE CODE		DWG NO	
A		3FKR5		SM3321	
SCALE				SHEET	
				REV	
				--	