

TNC/F-BNC/M ADAPTER

SM3575

SPECIFICATIONS


ELECTRICAL

FREQUENCY: 0-4 GHZ
IMPEDANCE: 50 OHMS
VSWR: 1.2:1 MAX @ 4GHZ

MECHANICAL

MATERIALS BODY : NICKLE PLATED BRASS
MATERIAL CONTACTS: FEMALE BeCU, MALE BRASS
CONTACT PLATING: Au PER MIL-G-45204
INTERFACE: MIL-STD-348A
DIELECTRIC: TEFLON

TEMP: -55 TO 125 °C

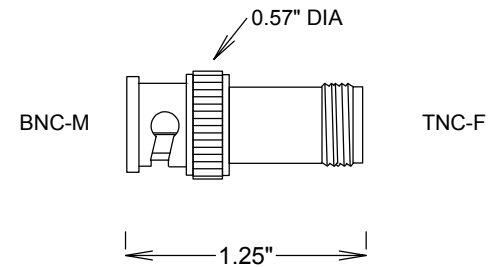

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

TNC/F-BNC/M ADAPTER

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SM3575	-

SCALE

SHEET