

BNC/F-SMB/JACK 4GHZ 75 OHMS

SM3648


SPECIFICATIONS

ELECTRICAL

FREQUENCY: 0-4 GHZ
 IMPEDENCE: 75 OHMS
 VSWR: 1.2:1 MAX

MECHANICAL

MATERIAL BODY: NICKEL PLATED BRASS
 CONTACTS: BeCu
 INTERFACE: MIL-STD-348A
 ROHS COMPLIANT
 TEMPERATURE RATING: -55° +110°C

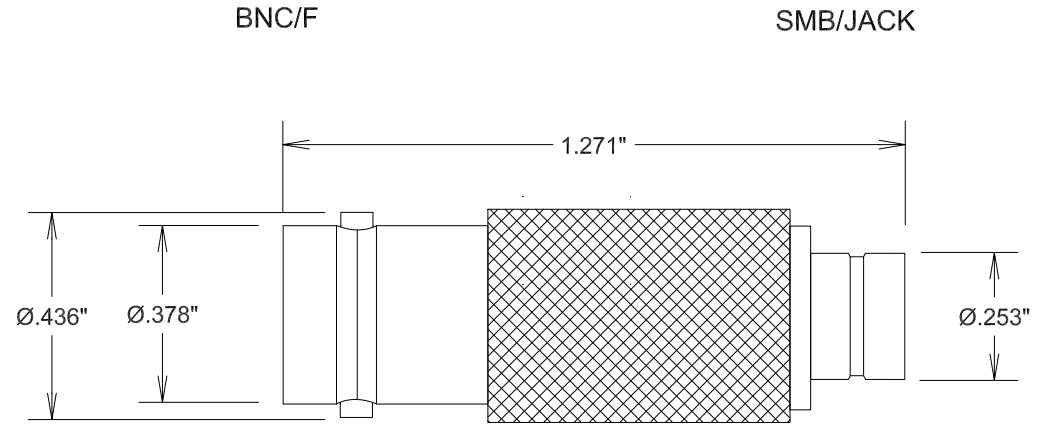

				FAIRVIEW MICROWAVE INC.	
				ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM	
				TITLE	
				BNC/F-SMB/JACK 4GHZ 75 OHMS	
SIZE		CAGE CODE	DWG NO		REV
A		3FKR5	SM3648		A
SCALE					SHEET