

HN-MALE TO BNC-FEMALE

SM3925


SPECIFICATIONS

ELECTRICAL

FREQUENCY: 0-4 GHZ
IMPEDANCE: 50 OHMS
VSWR: 1.2:1 MAX

MECHANICAL

MATERIAL BODY: NICKEL PLATED BRASS
CONTACTS MALE: BRASS, FEMALE: BeCu
CONTACT PLATING: Au MIL-G-45204
INSULATOR: TEFLON
INTERFACE: MIL-STD-348

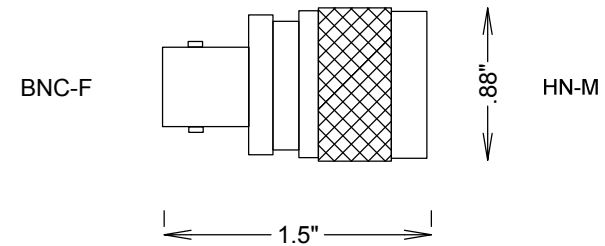

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

HN-MALE TO BNC-FEMALE

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SM3925	--

SCALE

SHEET