

N-SMA F/F 18GHZ FLANGE ADAPTER

SM4233

SPECIFICATIONS

ELECTRICAL

FREQUENCY: 0-18 GHZ
 IMPEDANCE: 50 OHMS
 VSWR: 1.15:1 MAX
 VRMS: 250 V SEA LEVEL



MECHANICAL

MATERIALS BODY PASSIVATED STAINLESS STEEL
 MATERIALS CONTACTS BeCu
 CONTACT PLATING: Au PER MIL-G-45204
 CONTACT CAPTIVATION: 6LBS MIN AXIAL FORCE
 CONTACT TORQUE: 4 IN-OUNCES MIN
 INTERFACE: MIL-STD-348A
 DURABILITY: 500 CYCLES MIN

ENVIRONMENTAL

CORROSION MIL-STD-202
 VIBRATION MIL-STD-202
 SHOCK MIL-STD-202

ROHS COMPLIANT

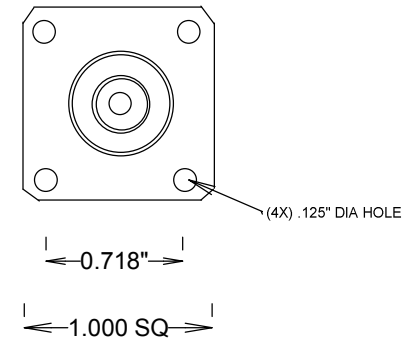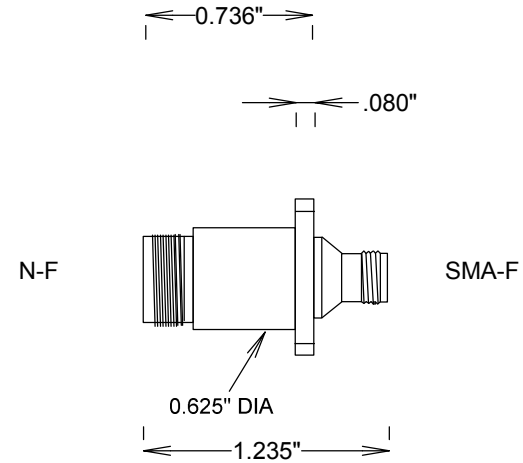

				FAIRVIEW MICROWAVE INC.	
				ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM	
				TITLE	
				N-SMA F/F 18GHZ FLANGE ADAPTER	
SIZE	CAGE CODE	DWG NO	SM4233		
A	3FKR5				
SCALE			SHEET		REV B