

N - 7/16 ADAPTERS

SM4677, SM4682, SM4687, SM4692

SPECIFICATIONS

ELECTRICAL


FREQUENCY: 0-6 GHZ
 IMPEDANCE: 50 OHMS
 VSWR: 1.15:1 MAX
 PIM; 160dbc typ for 2 carriers @ 20W

MECHANICAL

MATERIALS BODY: TRIMETAL PLATED BRASS
 MATERIALS CONTACTS: SI PLATING
 RECOMMENDED TORQUE 7-16 221 IN-LBS
 DURABILITY: 500 CYCLES MIN

OPERATING TEMP: -55° TO +125° C

ROHS COMPLIANT

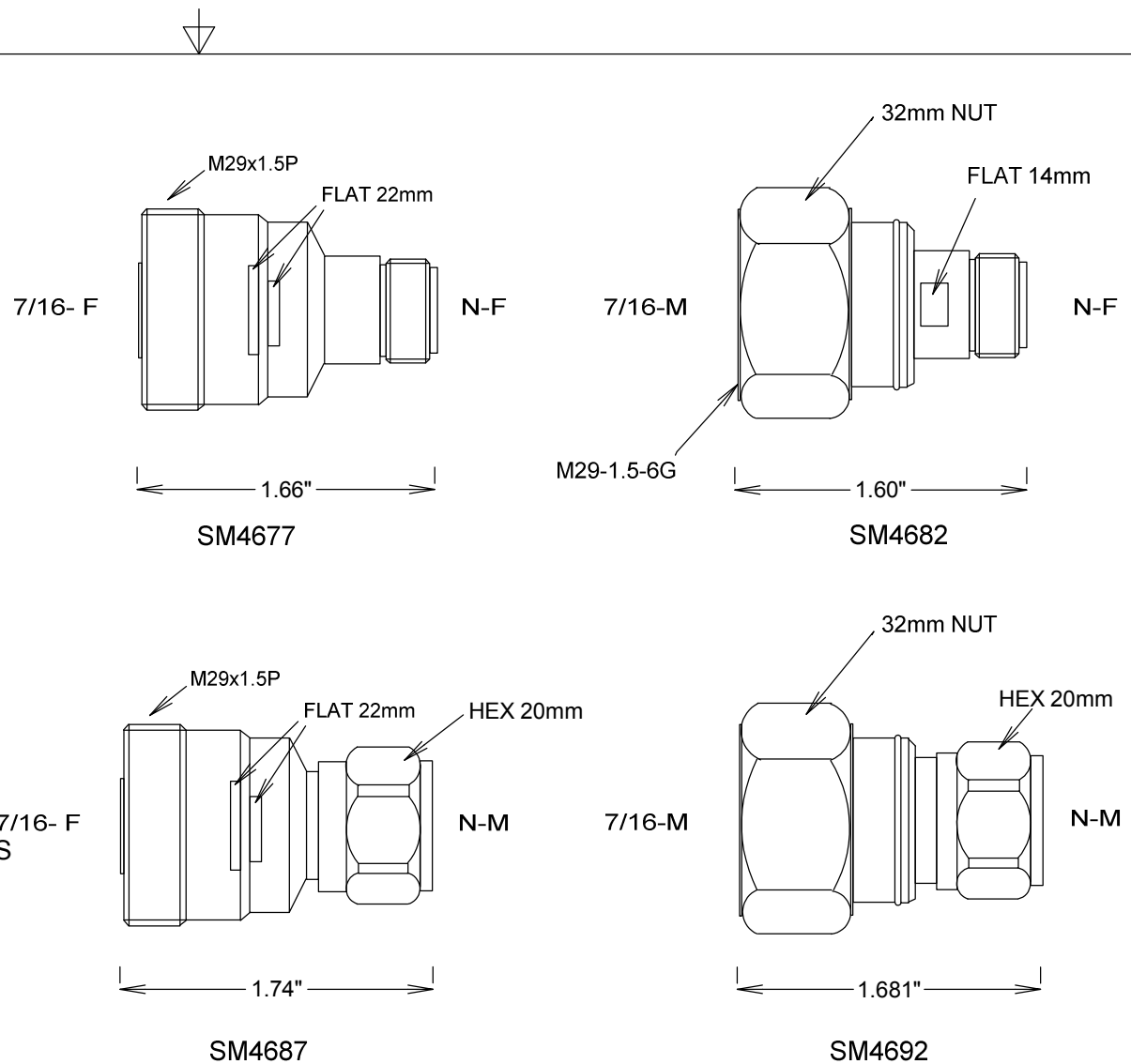

				FAIRVIEW MICROWAVE INC.			
				ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM			
				TITLE			
				N - 7/16 ADAPTERS			
SIZE		CAGE CODE		DWG NO		REV	
A		3FKR5		SM4677, SM4682, SM4687, SM4692		A	
SCALE				SHEET			