

SMA-TNC 18GHZ PRECISION ADAPTERS

SM4758, 4762, 4768, 4772

SPECIFICATIONS

ELECTRICAL

FREQUENCY: 0-18 GHZ
 IMPEDANCE: 50 OHMS
 VSWR: 1.15:1 MAX
 VRMS: 250 V SEA LEVEL


MECHANICAL

MATERIALS BODY PASS STAINLESS STEEL
 MATERIALS CONTACTS BeCu
 CONTACT PLATING: Au PER MIL-G-45204
 CONTACT CAPTIVATION: 6LBS MIN AXIAL FORCE
 CONTACT TORQUE: 4 IN-OUNCES MIN
 DURABILITY: 500 CYCLES MIN

ENVIRONMENTAL

CORROSION MIL-STD-202
 VIBRATION MIL-STD-202
 SHOCK MIL-STD-202

ROHS COMPLIANT

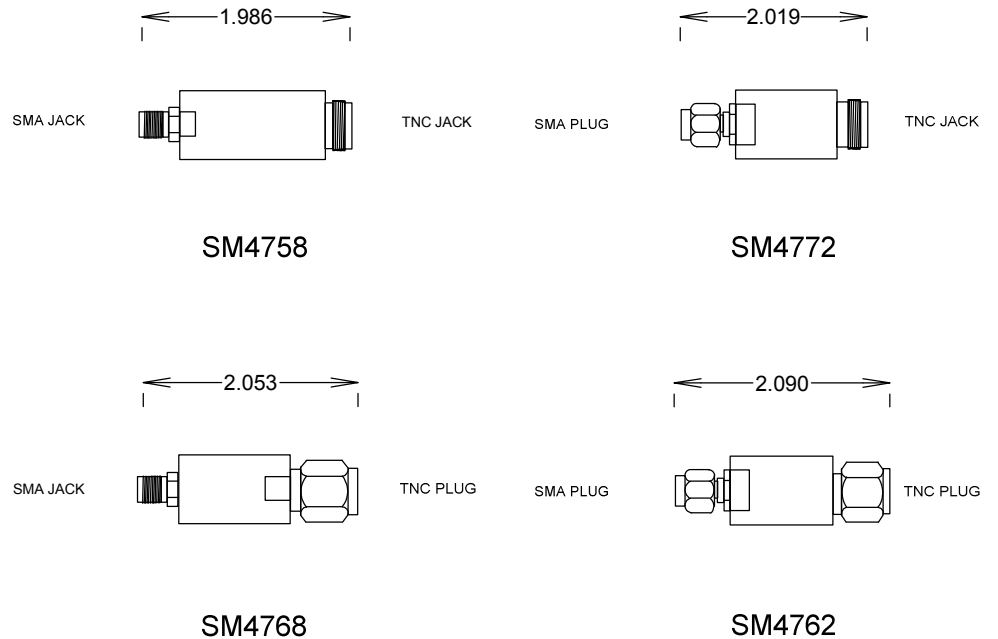

				FAIRVIEW MICROWAVE INC.			
				ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM			
				TITLE			
				SMA-TNC 18GHZ PRECISION ADAPTERS			
SIZE	CAGE CODE	DWG NO		REV			
A	3FKR5	SM4758, 4762, 4768, 4772		B			
SCALE			SHEET				