

# SMA/M - SMA/F BULKHEAD ADAPTER

SM4929

## SPECIFICATIONS

### ELECTRICAL


FREQUENCY: 0-18 GHZ  
 IMPEDANCE: 50 OHMS  
 VSWR: 1.20:1 MAX

### MECHANICAL

MATERIALS BODY NICKEL PLATED BRASS  
 MATERIALS CONTACTS BeCu  
 PLATING CONTACTS: Au PER MIL-G-45204  
 DURABILITY: 100 CYCLES MIN  
 INSULATOR: TEFLON  
 INTERFACE: MIL-STD-348A

STORAGE TEMP: -65°+165 °C  
 OPERATING TEMP: -55°+120 °C

ROHS COMPLIANT

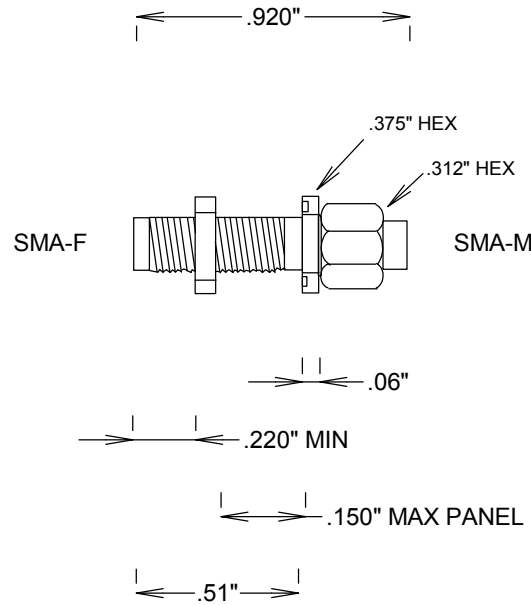

SUPPLIED WITH GASKET & NUT

RECOMMENDED PANEL CUTOUT

				<b>FAIRVIEW MICROWAVE INC.</b>			
				ALLEN, TX 75013 <a href="http://WWW.FAIRVIEWMICROWAVE.COM">WWW.FAIRVIEWMICROWAVE.COM</a>			
				TITLE			
				SMA/M - SMA/F BULKHEAD ADAPTER			
		SIZE	CAGE CODE	DWG NO		REV	
		<b>A</b>	<b>3FKR5</b>	<b>SM4929</b>		<b>D</b>	
				SCALE		SHEET	