


ADAPTER SMP/M-SMA/M 26.5GHZ FULL DET

SM8807

SPECIFICATIONS

ELECTRICAL:
 FREQUENCY: 0-26.5 GHZ
 IMPEDANCE: 50 OHMS
 VSWR: 1.2:1 MAX

MECHANICAL:
 MATERIAL SMP BODY: BeCu
 MATERIAL SMA BODY: PASS S STEEL
 CENTER CONTACT SMP: BeCu
 CENTER CONTACT SMA: BRASS
 CONTACT PLATING: Au PER MIL-G-45204
 INSULATOR: PTFE
 INTERFACE: SMP MIL-STD-348
 INTERFACE: SMA MIL-STD-348
 OP. TEMP RANGE: -55° to +125°C
 ROHS COMPLIANT
 SMP FORCE TO ENGAGE: 15.0 LBS MAX
 SMP FORCE TO DISENGAGE: 5.0 LBS MIN

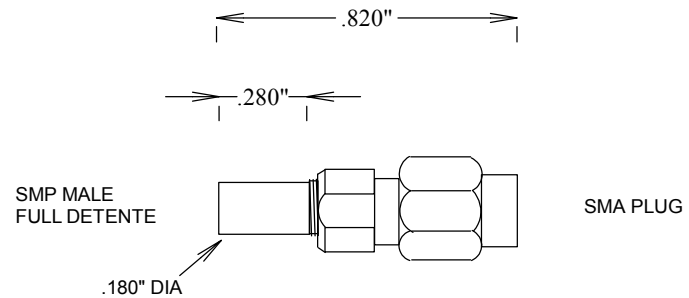

				FAIRVIEW MICROWAVE INC.	
				ALLEN, TX 75013 WWW.FAIRVIEMICROWAVE.COM	
				TITLE	
				ADAPTER SMP/M-SMA/M 26.5GHZ FULL DET	
SIZE	CAGE CODE	DWG NO	SM8807		
A	3FKR5				
SCALE			SHEET		