


ADAPTER MINISMP/M-SMA/F 26.5GHZ FULL DETENTE

SM8908

SPECIFICATIONS

ELECTRICAL:
 FREQUENCY: 0-26.5 GHZ
 IMPEDANCE: 50 OHMS
 VSWR: 1.2:1 MAX

MECHANICAL:
 MATERIAL BODY: PASS S STEEL
 CENTER CONTACTS: BeCU
 CONTACT PLATING: Au PER MIL-G-45204
 INSULATOR: PTFE
 INTERFACE: SMA MIL-STD-348B
 OP. TEMP RANGE: -55° to +125°C
 ROHS COMPLIANT
 SMP FORCE TO ENGAGE: 4.0 LBS MAX
 SMP FORCE TO DISENGAGE: 2.5 LBS MIN

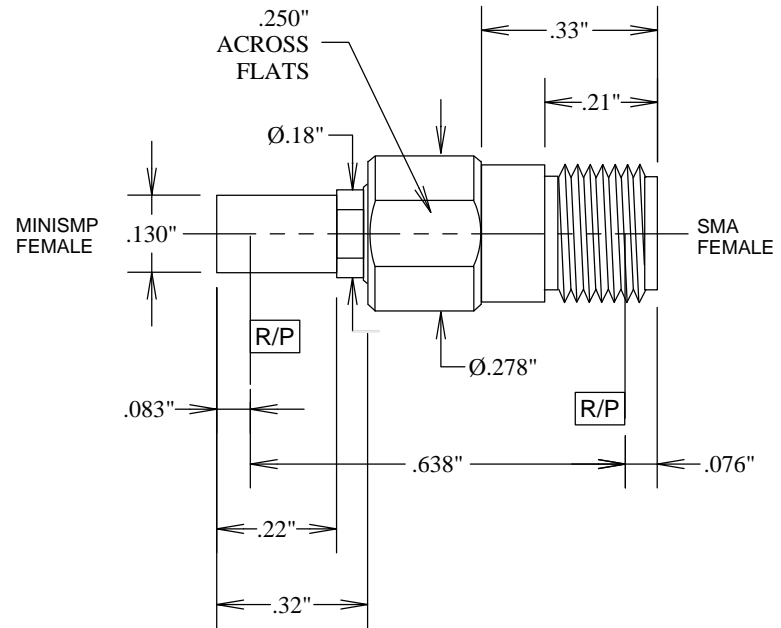

				FAIRVIEW MICROWAVE INC.	
				ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM	
				TITLE	
				ADAPTER MINISMP/M-SMA/F 26.5GHZ FULL DETENTE	
SIZE	CAGE CODE	DWG NO	REV		
A	3FKR5	SM8908	A		
SCALE			SHEET		