

ADAPTER MINI SMP/M FD-2.92/M 40GHZ

SM8927


SPECIFICATIONS

ELECTRICAL:

FREQUENCY: 0-40 GHZ
 IMPEDANCE: 50 OHMS
 VSWR: 1.25:1 MAX

MECHANICAL:

MATERIAL SMP BODY: BeCu
 MATERIAL 2.92 BODY: PASS S STEEL
 CENTER CONTACTS: BeCu
 PLATING: Au PER MIL-G-45204
 INSULATOR: PTFE
 INTERFACE: SMP DESC 94007
 INTERFACE: 2.92 MIL-STD-348B
 OP. TEMP RANGE: -55° to +125°C
 ROHS COMPLIANT
 FORCE TO ENGAGE: 4.0 LBS MAX
 FORCE TO DISENGAGE: 2.5 LBS MIN

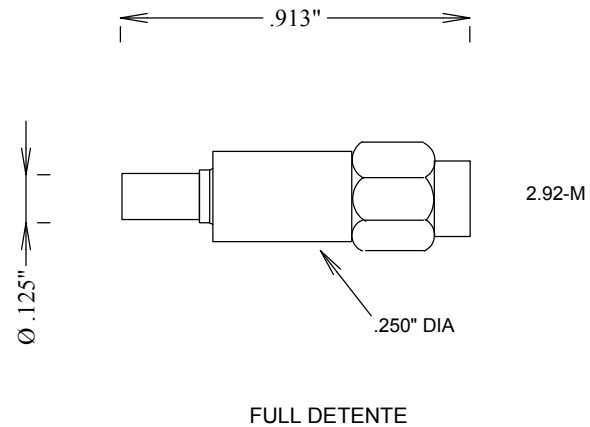

				FAIRVIEW MICROWAVE INC.	
				ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM	
				TITLE	
				ADAPTER MINI SMP/M FD-2.92/M 40GHZ	
SIZE	CAGE CODE	DWG NO	REV		
A	3FKR5	SM8927	A		
SCALE			SHEET		