


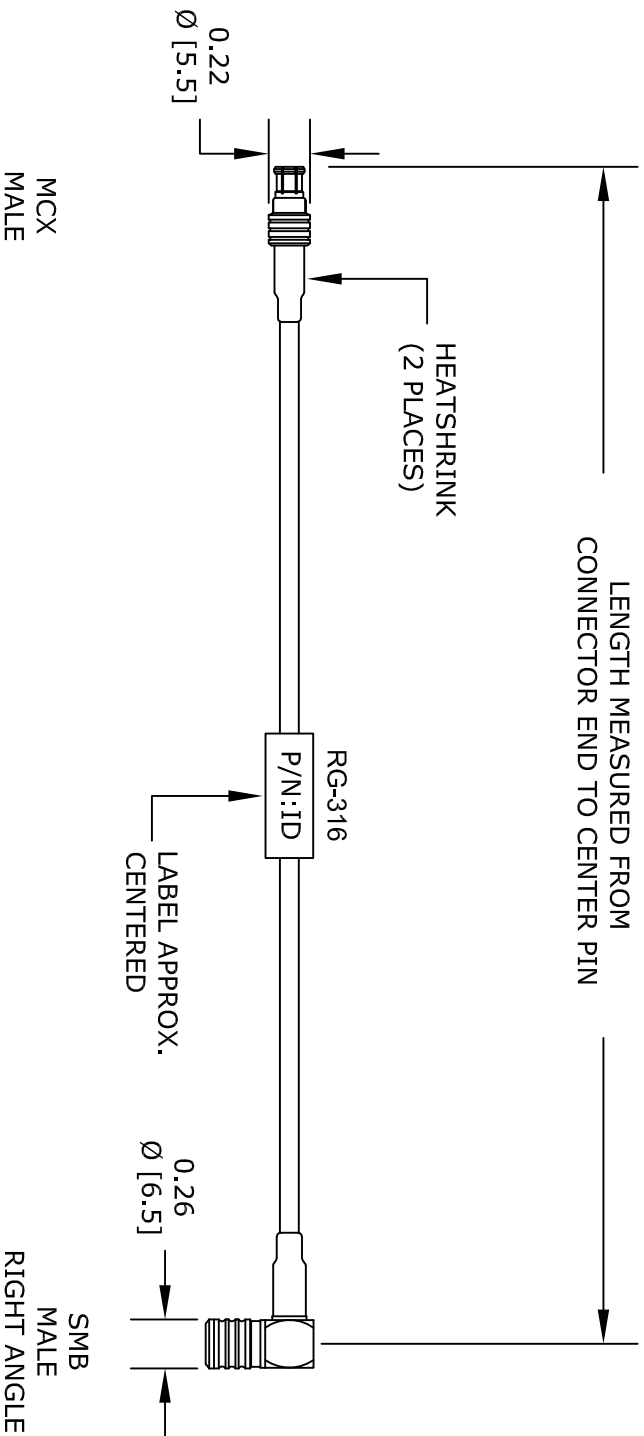

NOTE:  
FOR LONGER CABLES (>10FT.) THERE ARE  
TWO LABELS, ONE NEAR EACH END.

| How To Order                     |                     | Part # Ext.     | Length In Inches | Part # Ext.   | Length In Centimeters |
|----------------------------------|---------------------|-----------------|------------------|---------------|-----------------------|
| <u>Part Number Configuration</u> |                     | <u>Examples</u> |                  |               |                       |
| FMC                              | zzzzzzz - [xx] [uu] | FMC000-100      | -12              | 12"           | -25cm                 |
|                                  |                     | FMC000-100cm    | -24              | 24"           | -50cm                 |
|                                  |                     |                 | -36              | 36"           | -75cm                 |
|                                  |                     |                 | -48              | 48"           | -100cm                |
|                                  |                     |                 | -60              | 60"           | -125cm                |
|                                  |                     |                 | -xx              | Custom Length | Custom Length         |

cm = Centimeters  
< Blank > = Inches  
Length

**FAIRVIEW MICROWAVE INC.**  
ALLEN, TX 75013 [WWW.FAIRVIEWMICROWAVE.COM](http://WWW.FAIRVIEWMICROWAVE.COM)

NOTES:  
1. UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE NOMINAL.  
2. ALL SPECIFICATIONS ARE SUBJECT TO CHANGE WITHOUT NOTICE AT ANY TIME.  
3. DIMENSIONS ARE IN INCHES [mm].

|          |        |               |       |           |      |
|----------|--------|---------------|-------|-----------|------|
| TITLE    |        | DWG NO        |       | CAGE CODE |      |
|          |        | FMC0726315-12 |       | 3FKR5     |      |
| CAD FILE | 091914 | SHEET         | SCALE | N/A       | SIZE |
|          |        |               |       |           | A    |
|          |        |               |       |           | 150  |