

**N Male to N Female Bulkhead Cable RG-316 Coax in 12 Inch**

**Electrical Specifications**

| Description             | Min | Typ         | Max    | Units        |
|-------------------------|-----|-------------|--------|--------------|
| Frequency Range         | DC  |             | 2      | GHz          |
| VSWR                    |     |             | 1.35:1 |              |
| Velocity of Propagation |     | 70          |        | %            |
| Capacitance             |     | 32 [104.99] |        | pF/ft [pF/m] |

**Mechanical Specifications**

**Cable Assembly**

|        |                    |
|--------|--------------------|
| Length | 12 in [304.8 mm]   |
| Weight | 0.166 lbs [75.3 g] |

**Cable**

|                                      |                            |
|--------------------------------------|----------------------------|
| Cable Type                           | RG-316                     |
| Impedance                            | 50 Ohms                    |
| Inner Conductor Type                 | Solid                      |
| Inner Conductor Material and Plating | Copper, Silver             |
| Dielectric Type                      | PTFE                       |
| Number of Shields                    | 1                          |
| Shield Layer 1                       | Silver Plated Copper Braid |
| Jacket Material                      | FEP, Tan                   |
| Jacket Diameter                      | 0.098 in [2.49 mm]         |

**Connectors**

| Description                | Connector 1            | Connector 2            |
|----------------------------|------------------------|------------------------|
| Type                       | N Male                 | N Female Bulkhead      |
| Impedance                  | 50 Ohms                | 50 Ohms                |
| Configuration              | Straight               | Straight               |
| Contact Material & Plating | Beryllium Copper, Gold | Beryllium Copper, Gold |
| Contact Plating Spec.      | 30μ in. minimum        | 30μ in. minimum        |
| Dielectric Type            | PTFE                   | PTFE                   |
| Hex Size                   |                        | 3/4 inch               |
| Body Material & Plating    | Brass, Nickel          | Brass, Nickel          |
| Body Plating Spec.         | 100μ in. minimum       | 100μ in. minimum       |

**Environmental Specifications**

**Temperature**

|                 |                   |
|-----------------|-------------------|
| Operating Range | -65 to +165 deg C |
|-----------------|-------------------|

**Compliance Certifications** (visit [www.FairviewMicrowave.com](http://www.FairviewMicrowave.com) for current document)

**Plotted and Other Data**

Notes:




**Configuration:**

- N Male
- N Female Bulkhead
- RG-316

Fairview Microwave  
 1130 Junction Dr. #100  
 Allen, TX 75013  
 Tel: 1-800-715-4396 / (972) 649-6678  
 Fax: (972) 649-6689  
[www.fairviewmicrowave.com](http://www.fairviewmicrowave.com)  
[sales@fairviewmicrowave.com](mailto:sales@fairviewmicrowave.com)

**Typical Performance Data**

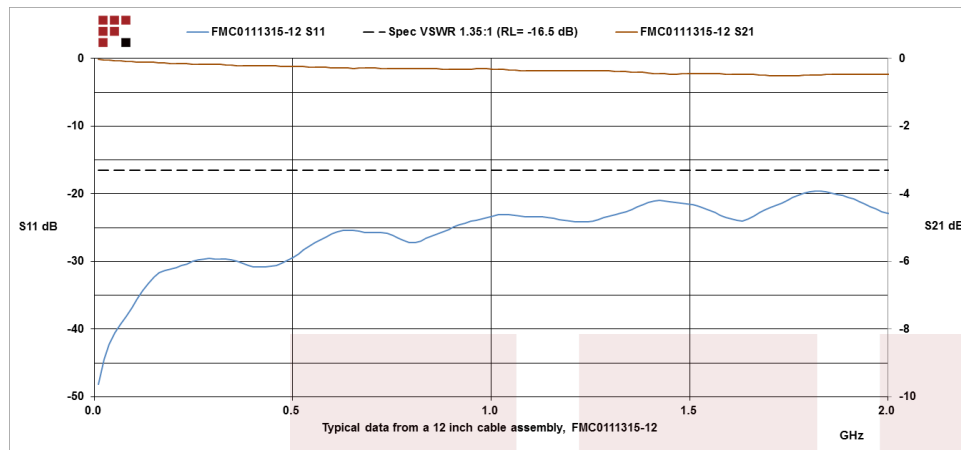

**How to Order**

Part Number Configuration:

**FMC0111315 - xx uu**

cm = Centimeters  
 <blank> = Inches  
 Length


Example: FMC0111315-12 = 12 inches long cable  
 FMC0111315-100cm = 100 cm long cable

N Male to N Female Bulkhead Cable RG-316 Coax in 12 Inch from Fairview Microwave has same day shipment for domestic and International orders. Our RF, microwave and fiber optic products maintain a 99% availability and are part of the broadest selection in the industry.

Click the following link to obtain additional part information: [N Male to N Female Bulkhead Cable RG-316 Coax in 12 Inch FMC0111315-12](#)

URL: <http://www.fairviewmicrowave.com/standard-n-male-n-female-cable-rg316-coax-fmc0111315-12-p.aspx>

The information contained in this document is accurate to the best of our knowledge and representative of the part described herein. It may be necessary to make modifications to the part and/or the documentation of the part, in order to implement improvements. Fairview Microwave reserves the right to make such changes as required. Unless otherwise stated, all specifications are nominal. Fairview Microwave does not make any representation or warranty regarding the suitability of the part described herein for any particular purpose, and Fairview Microwave does not assume any liability arising out of the use of any part or documentation.

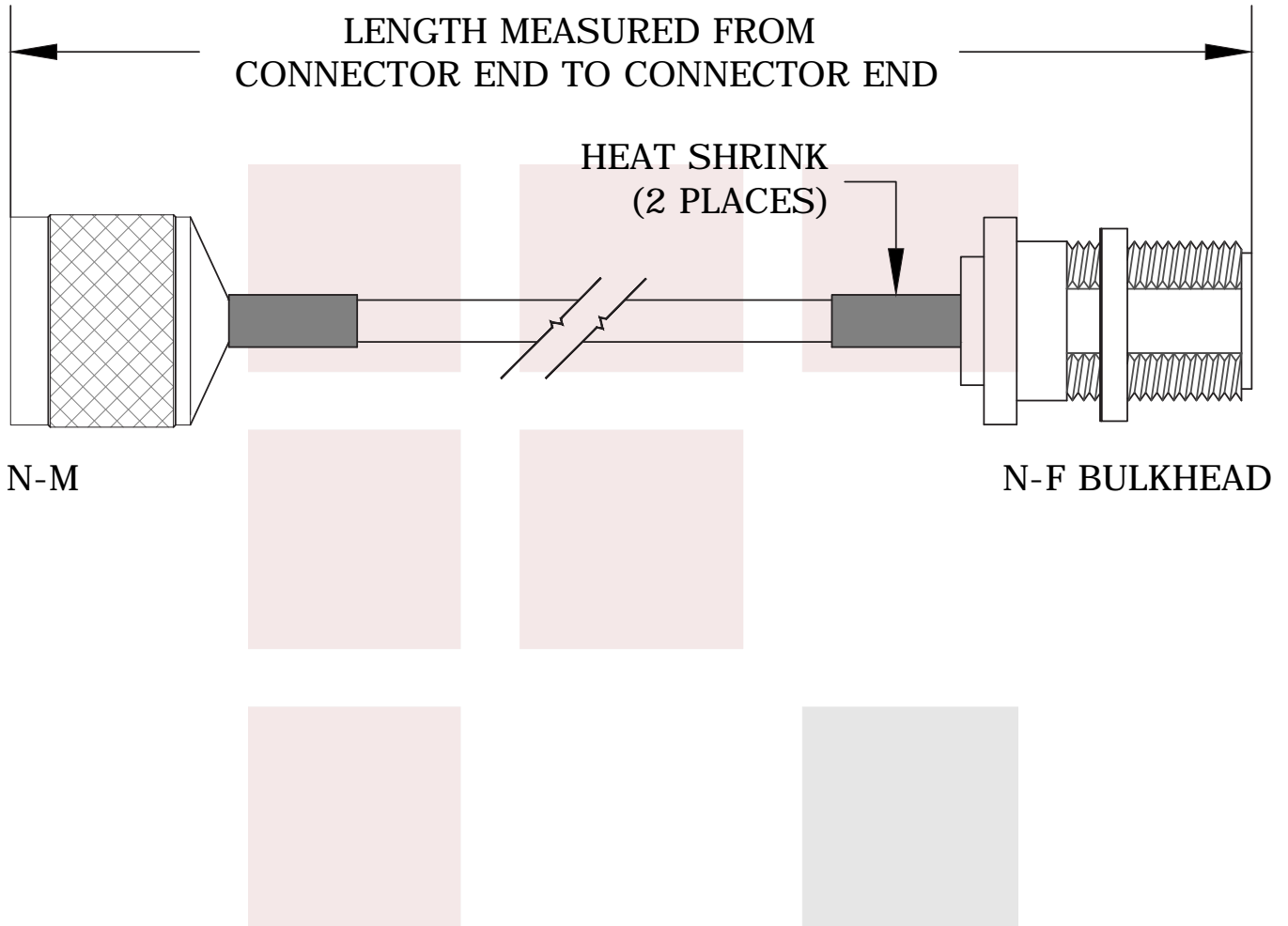

|   |   |        |       |                        |     |      |   |
|---|---|--------|-------|------------------------|-----|------|---|
| <b>FAIRVIEW MICROWAVE INC.</b><br>ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM | NOTES:<br>1. UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE NOMINAL.<br>2. ALL SPECIFICATIONS ARE SUBJECT TO CHANGE WITHOUT NOTICE AT ANY TIME.<br>3. DIMENSIONS ARE IN INCHES [mm]. |        |       |                        |     |      |   |
|   | DWG NO <b>FMC0111315</b>  |        |       | CAGE CODE <b>3FKR5</b> |     |      |   |
|   | CAD FILE  | 022506 | SHEET | SCALE                  | N/A | SIZE | A |

N Male to N Female Bulkhead Cable RG-316 Coax in 12 Inch