

## N Male to RA N Male Cable RG-214 Coax in 12 Inch with LF Solder

The type N male to RA type N male 12 inch cable using RG-214 coax, part number FMC0142214LF-12, from Fairview Microwave is in-stock and ships same day. This Fairview type N to type N cable assembly has a male to male gender configuration with 50 ohm flexible RG-214 coax. Fairview Microwave's flexible RF cable assemblies are ideal for applications where tight bends and continual flexure are required. The FMC0142214LF-12 type N male to type N male cable assembly operates to 5 GHz. The right angle type N interface on the RG-214 cable allows for easier connections in tight spaces. The double shielding of this Fairview cable assembly provides excellent shielding effectiveness.

Custom versions of most RF cable assemblies can be built and shipped same day. Custom cable assembly lengths can be obtained by specifying the desired length on the web site at time of order or by contacting a sales representative. Other RF cable assembly value added services including connector orientation or clocking, heat shrink booting and labeling are also available. RF testing can also be performed to document the electrical performance of your cable assembly.

### Electrical Specifications

Description	Min	Typ	Max	Units
Frequency Range	DC		5	GHz
VSWR			1.35:1	
Velocity of Propagation		66		%
Capacitance	30.94	[101.51]		pF/ft [pF/m]

### Mechanical Specifications

#### Cable Assembly

Length\* 12 in [304.8 mm]

#### Cable

Cable Type RG-214  
 Impedance 50 Ohms  
 Inner Conductor Type Stranded  
 Inner Conductor Material and Plating Copper, Silver  
 Dielectric Type PE  
 Number of Shields 2  
 Shield Layer 1 Silver Plated Copper Braid  
 Shield Layer 2 Silver Plated Copper Braid  
 Jacket Material PVC, Black  
 Jacket Diameter 0.425 in [10.8 mm]

#### Connectors

Description	Connector 1	Connector 2
Type	N Male	N Male
Configuration	Straight	Right Angle
Impedance	50 Ohms	50 Ohms
Contact Material & Plating	Brass, Gold	Brass, Gold
Body Material & Plating	Brass, Nickel	Brass, Nickel



### Configuration:

- N Male
- N Male Right Angle
- RG-214

### Features:

- Max Frequency 5 GHz
- 66% Phase Velocity
- Double Shielded
- PVC Jacket

### Applications:

- General Purpose
- Laboratory Use

Fairview Microwave  
 301 Leora Ln., Suite 100  
 Lewisville, TX 75056  
 Tel: 1-800-715-4396 / (972) 649-6678  
 Fax: (972) 649-6689  
[www.fairviewmicrowave.com](http://www.fairviewmicrowave.com)  
[sales@fairviewmicrowave.com](mailto:sales@fairviewmicrowave.com)

## Environmental Specifications

### Temperature

Operating Range -55 to +155 deg C

## Compliance Certifications (see [product page](#) for current document)

## Plotted and Other Data

Notes:

## How to Order

Part Number Configuration:

**FMC0142214LF - xx uu**

cm = Centimeters  
<blank> = Inches

Length


Example: FMC0142214LF-12 = 12 inches long cable  
FMC0142214LF-100cm = 100 cm long cable

N Male to RA N Male Cable RG-214 Coax in 12 Inch with LF Solder from Fairview Microwave has same day shipment for domestic and International orders. Our RF, microwave and millimeter wave products maintain a 99% availability and are part of the broadest selection in the industry.

Click the following link to obtain additional part information: [N Male to RA N Male Cable RG-214 Coax in 12 Inch with LF Solder FMC0142214LF-12](#)

URL: <https://www.fairviewmicrowave.com/standard-n-male-ra-n-male-cable-rg214-coax-fmc0142214lf-12-p.aspx>

The information contained in this document is accurate to the best of our knowledge and representative of the part described herein. It may be necessary to make modifications to the part and/or the documentation of the part, in order to implement improvements. Fairview Microwave reserves the right to make such changes as required. Unless otherwise stated, all specifications are nominal. Fairview Microwave does not make any representation or warranty regarding the suitability of the part described herein for any particular purpose, and Fairview Microwave does not assume any liability arising out of the use of any part or documentation.

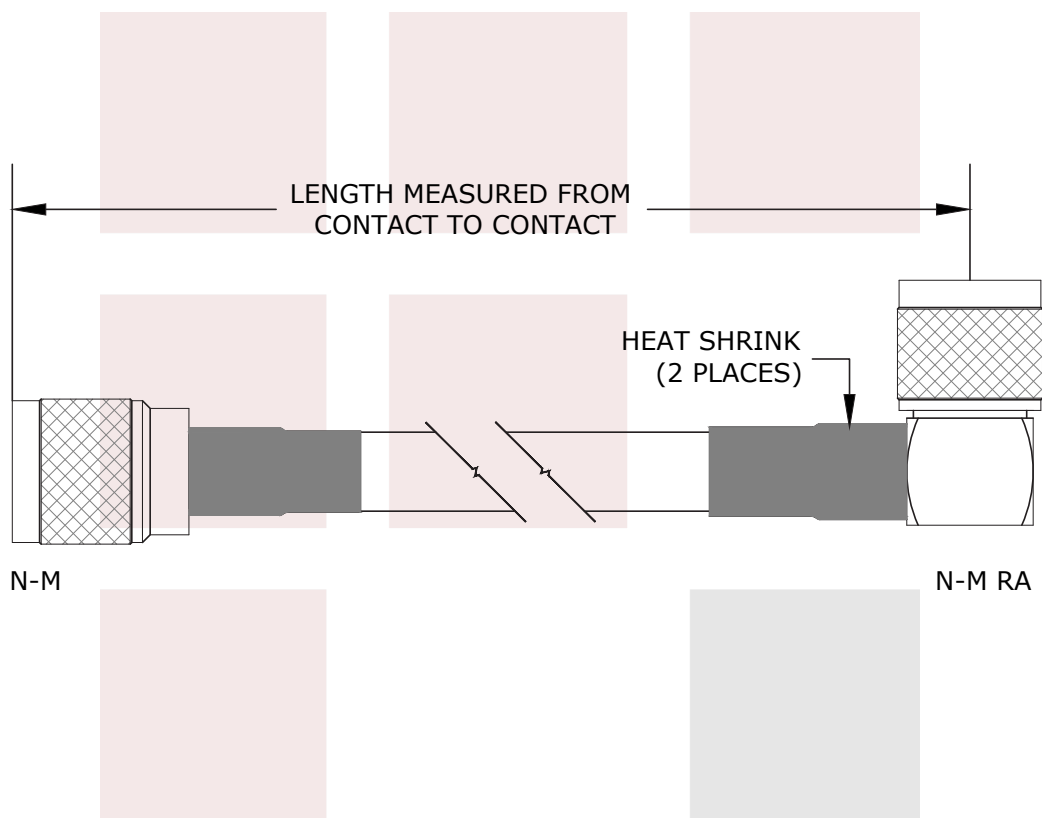

## FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

### NOTES:

1. UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE NOMINAL.
2. ALL SPECIFICATIONS ARE SUBJECT TO CHANGE WITHOUT NOTICE AT ANY TIME.
3. DIMENSIONS ARE IN INCHES [mm].

### TITLE

N Male to RA N Male Cable RG-214 Coax in 12 Inch  
with LF Solder

### DWG NO

FMC0142214LF

### CAGE CODE

3FKR5

### CAD FILE

101014

### SHEET

### SCALE

N/A

### SIZE

A

5568