

SMA Male to N Female Bulkhead Cable LMR-200-FR Coax in 6 Inch and RoHS

The SMA male to type N female bulkhead 6 inch cable using LMR-200-FR coax, part number FMC0211202LF-06, from Fairview Microwave is in-stock and ships same day. This Fairview SMA to type N cable assembly has a male to female gender configuration with 50 ohm flexible LMR-200-FR coax. Fairview Microwave's flexible RF cable assemblies are ideal for applications where tight bends and continual flexure are required. The FMC0211202LF-06 SMA male to type N female cable assembly operates to 3 GHz. Our RF cable assembly with type N bulkhead interface allows designers to create external connections on their product enclosures, and can be used in a variety of other rack mount and panel mount applications. The double shielding of this Fairview cable assembly provides excellent shielding effectiveness of better than -90 dB.

Custom versions of most RF cable assemblies can be built and shipped same day. Custom cable assembly lengths can be obtained by specifying the desired length on the web site at time of order or by contacting a sales representative. Other RF cable assembly value added services including connector orientation or clocking, heat shrink booting and labeling are also available. RF testing can also be performed to document the electrical performance of your cable assembly.

Electrical Specifications

Description	Min	Typ	Max	Units
Frequency Range	DC		3	GHz
VSWR			1.35:1	
Velocity of Propagation		83		%
RF Shielding	-90			dB
Capacitance		24.5 [80.38]		pF/ft [pF/m]

Mechanical Specifications

Cable Assembly

Length*	6 in [152.4 mm]
Diameter	0.78 in [19.81 mm]

Cable

Cable Type	LMR-200-FR
Impedance	50 Ohms
Inner Conductor Type	Solid
Inner Conductor Material and Plating	Copper, Silver
Dielectric Type	PTFE
Number of Shields	2
Shield Layer 1	Silver Plated Copper Tape
Shield Layer 2	Silver Plated Copper Braid
Jacket Material	FEP, Black
Jacket Diameter	0.163 in [4.14 mm]



Configuration:

- SMA Male
- N Female Bulkhead
- LMR-200-FR

Features:

- Max Frequency 3 GHz
- Shielding Effectivity > -90 dB
- 83% Phase Velocity
- Double Shielded
- FEP Jacket

Applications:

- General Purpose
- Laboratory Use

Fairview Microwave
301 Leora Ln., Suite 100
Lewisville, TX 75056
Tel: 1-800-715-4396 / (972) 649-6678
Fax: (972) 649-6689
www.fairviewmicrowave.com
sales@fairviewmicrowave.com

Connectors

Description	Connector 1	Connector 2
Type	SMA Male	N Female
Configuration	Straight	Straight
Mount Method		Bulkhead
Impedance	50 Ohms	50 Ohms
Contact Material & Plating	Brass, Gold	Beryllium Copper, Gold
Contact Plating Spec.	MIL-G-45204	
Dielectric Type	PTFE	PTFE
Body Material & Plating	Brass	Stainless Steel, Gold

Mechanical Specification Notes:

*All cable assemblies have a length tolerance of 1.5% or $\pm 3/8"$, whichever is greater.

Environmental Specifications

Temperature


Operating Range -65 to +125 deg C

Compliance Certifications (see [product page](#) for current document)

Plotted and Other Data

Notes:

Typical Performance Data

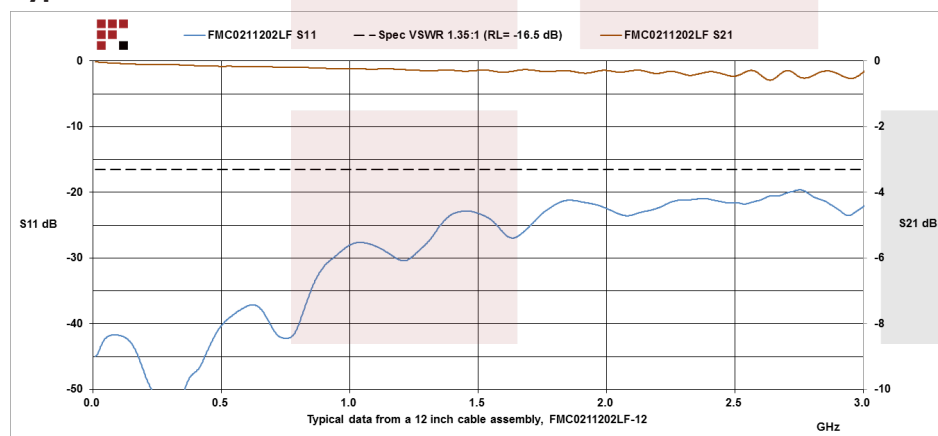

How to Order

Part Number Configuration:

FMC0211202LF - xx uu

cm = Centimeters
<blank> = Inches
Length

Example: FMC0211202LF-12 = 12 inches long cable
FMC0211202LF-100cm = 100 cm long cable


SMA Male to N Female Bulkhead Cable LMR-200-FR Coax in 6 Inch and RoHS from Fairview Microwave has same day shipment for domestic and International orders. Our RF, microwave and fiber optic products maintain a 99% availability and are part of the broadest selection in the industry.

Click the following link to obtain additional part information: [SMA Male to N Female Bulkhead Cable LMR-200-FR Coax in 6 Inch and RoHS FMC0211202LF-06](#)

URL: <https://www.fairviewmicrowave.com/sma-male-n-female-cable-lmr200fr-coax-fmc0211202lf-06-p.aspx>

The information contained in this document is accurate to the best of our knowledge and representative of the part described herein. It may be necessary to make modifications to the part and/or the documentation of the part, in order to implement improvements. Fairview Microwave reserves the right to make such changes as required. Unless otherwise stated, all specifications are nominal. Fairview Microwave does not make any representation or warranty regarding the suitability of the part described herein for any particular purpose, and Fairview Microwave does not assume any liability arising out of the use of any part or documentation.



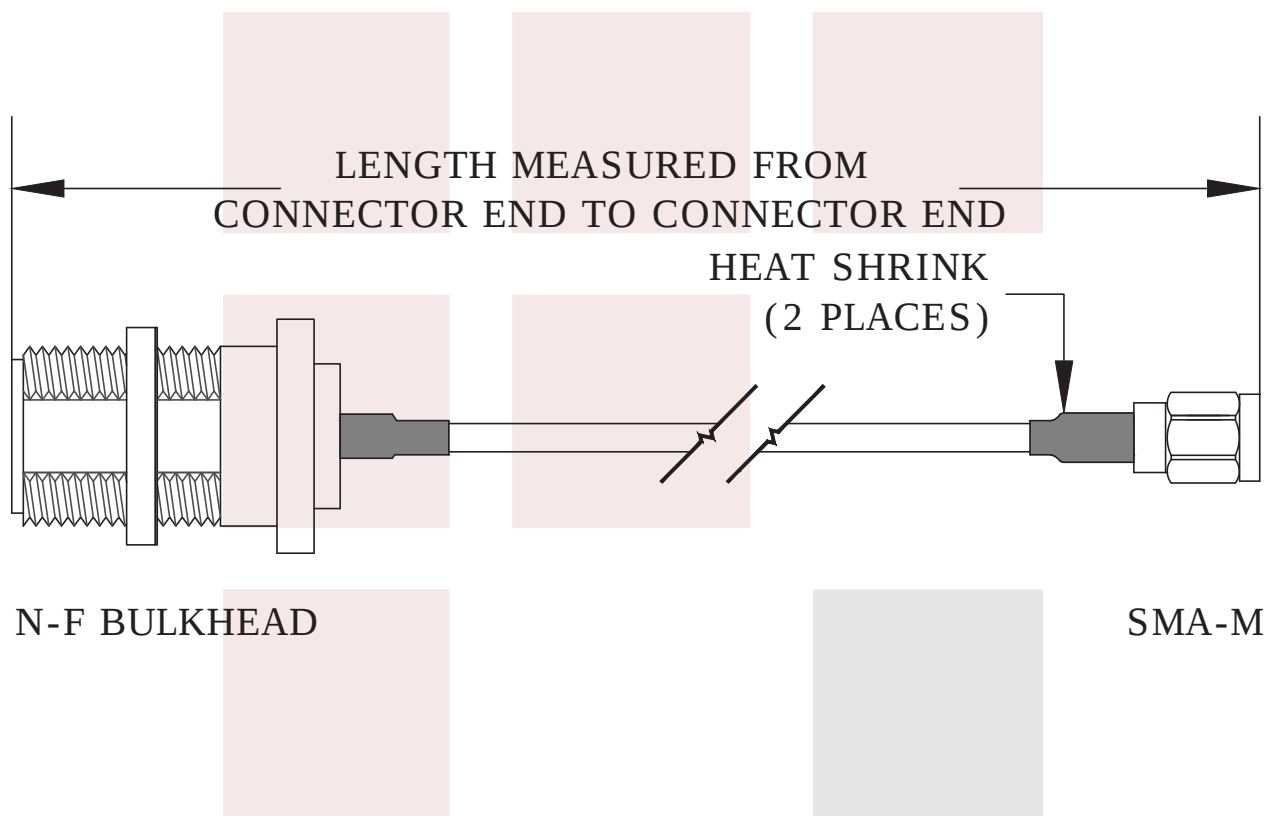

FAIRVIEW MICROWAVE INC. ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM		NOTES: 1. UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE NOMINAL. 2. ALL SPECIFICATIONS ARE SUBJECT TO CHANGE WITHOUT NOTICE AT ANY TIME. 3. DIMENSIONS ARE IN INCHES [mm].			
TITLE SMA Male to N Female Bulkhead Cable LMR-200-FR Coax in 6 Inch and RoHS		DWG NO FMC0211202LF		CAGE CODE 3FKR5	
CAD FILE	101514	SHEET	SCALE	N/A	SIZE A 5568