

## MCX Plug to BNC Female Bulkhead Cable RG-316 Coax in 48 Inch with LF Solder

The MCX plug to BNC female bulkhead 48 inch cable using RG-316 coax, part number FMC0738315LF-48, from Fairview Microwave is in-stock and ships same day. This Fairview MCX to BNC cable assembly has a plug to female gender configuration with 50 ohm flexible RG-316 coax. Fairview Microwave's flexible RF cable assemblies are ideal for applications where tight bends and continual flexure are required. The FMC0738315LF-48 MCX plug to BNC female cable assembly operates to 3 GHz. Our RF cable assembly with BNC bulkhead interface allows designers to create external connections on their product enclosures, and can be used in a variety of other rack mount and panel mount applications.

Custom versions of most RF cable assemblies can be built and shipped same day. Custom cable assembly lengths can be obtained by specifying the desired length on the web site at time of order or by contacting a sales representative. Other RF cable assembly value added services including connector orientation or clocking, heat shrink booting and labeling are also available. RF testing can also be performed to document the electrical performance of your cable assembly.



### Configuration:

- MCX Plug
- BNC Female Bulkhead
- RG-316

### Features:

- Max Frequency 3 GHz
- 70% Phase Velocity
- FEP Jacket

### Applications:

- General Purpose
- Laboratory Use

### Electrical Specifications

Description	Min	Typ	Max	Units
Frequency Range	DC		3	GHz
VSWR			1.35:1	
Velocity of Propagation		70		%
Capacitance		32 [104.99]		pF/ft [pF/m]

### Mechanical Specifications

#### Cable Assembly

Length*	48 in [121.92 cm]
Weight	0.086 lbs [39.01 g]

#### Cable

Cable Type	RG-316
Impedance	50 Ohms
Inner Conductor Type	Solid
Inner Conductor Material and Plating	Copper, Silver
Dielectric Type	PTFE
Number of Shields	1
Shield Layer 1	Silver Plated Copper Braid
Jacket Material	FEP, Tan
Jacket Diameter	0.098 in [2.49 mm]

Fairview Microwave  
 301 Leora Ln., Suite 100  
 Lewisville, TX 75056  
 Tel: 1-800-715-4396 / (972) 649-6678  
 Fax: (972) 649-6689  
[www.fairviewmicrowave.com](http://www.fairviewmicrowave.com)  
[sales@fairviewmicrowave.com](mailto:sales@fairviewmicrowave.com)

## Connectors

Description	Connector 1	Connector 2
Type	MCX Plug	BNC Female
Mount Method		Bulkhead
Impedance	50 Ohms	50 Ohms
Contact Material & Plating	Brass, Gold	Beryllium Copper, Gold
Contact Plating Spec.	30μ" Min	50μ in. minimum
Dielectric Type	PTFE	PTFE
Body Material & Plating	Brass, Gold	Brass, Nickel
Body Plating Spec.	3μ" Minimum	3μ in. minimum

## Environmental Specifications

### Temperature

Operating Range -55 to +155 deg C

## Compliance Certifications (see [product page](#) for current document)

## Plotted and Other Data

Notes:

## How to Order

Part Number Configuration:

**FMC0738315LF - xx uu**

cm = Centimeters  
 <blank> = Inches

Length


Example: FMC0738315LF-12 = 12 inches long cable  
 FMC0738315LF-100cm = 100 cm long cable

MCX Plug to BNC Female Bulkhead Cable RG-316 Coax in 48 Inch with LF Solder from Fairview Microwave has same day shipment for domestic and International orders. Our RF, microwave and millimeter wave products maintain a 99% availability and are part of the broadest selection in the industry.

Click the following link to obtain additional part information: [MCX Plug to BNC Female Bulkhead Cable RG-316 Coax in 48 Inch with LF Solder FMC0738315LF-48](#)

URL: <https://www.fairviewmicrowave.com/standard-mcx-plug-bnc-female-cable-rg316-coax-fmc0738315lf-48-p.aspx>

The information contained in this document is accurate to the best of our knowledge and representative of the part described herein. It may be necessary to make modifications to the part and/or the documentation of the part, in order to implement improvements. Fairview Microwave reserves the right to make such changes as required. Unless otherwise stated, all specifications are nominal. Fairview Microwave does not make any representation or warranty regarding the suitability of the part described herein for any particular purpose, and Fairview Microwave does not assume any liability arising out of the use of any part or documentation.

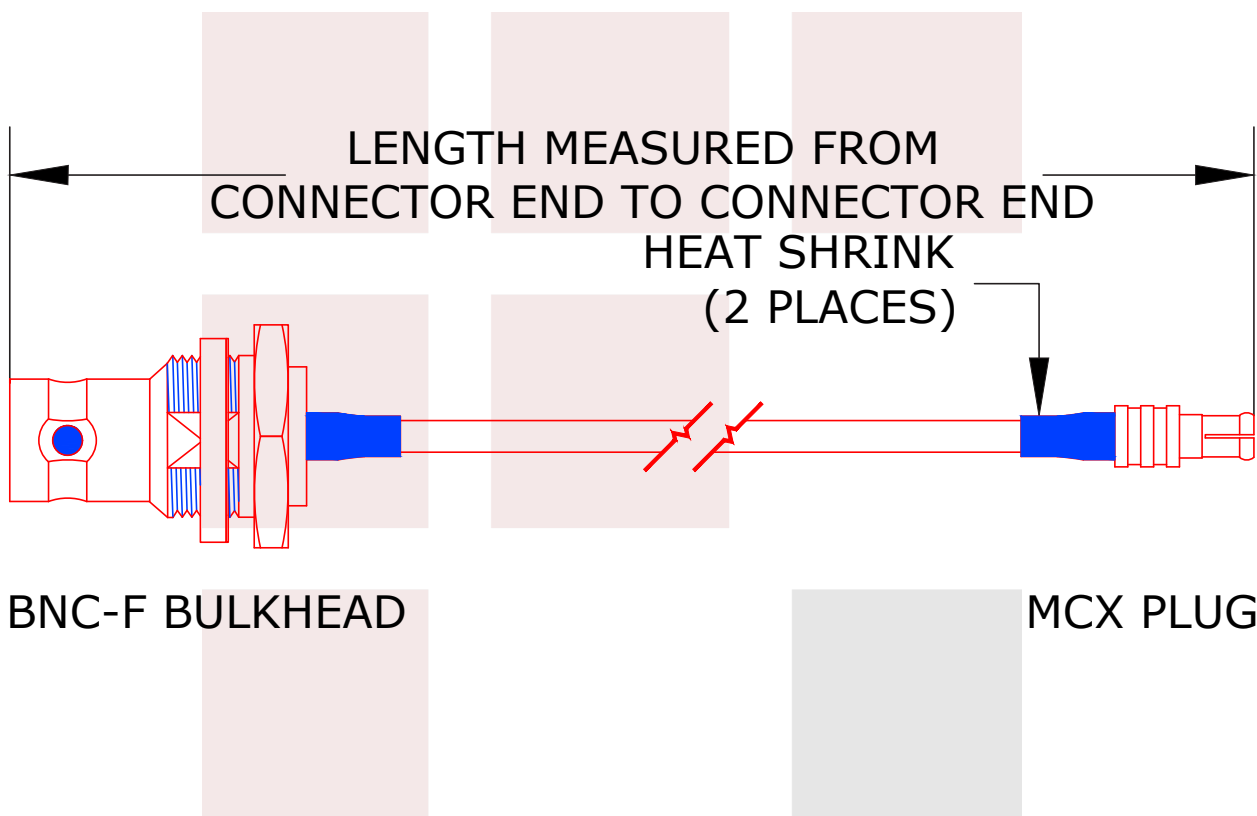

<b>FAIRVIEW MICROWAVE INC.</b> ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM		NOTES: 1. UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE NOMINAL. 2. ALL SPECIFICATIONS ARE SUBJECT TO CHANGE WITHOUT NOTICE AT ANY TIME. 3. DIMENSIONS ARE IN INCHES [mm].			
TITLE MCX Plug to BNC Female Bulkhead Cable RG-316 Coax in 48 Inch with LF Solder		DWG NO FMC0738315LF		CAGE CODE 3FKR5	
CAD FILE	102114	SHEET	SCALE	N/A	SIZE A 5568