

SMA Female to RA SMC Plug Cable RG-316 Coax in 60 Inch

Electrical Specifications

Frequency Range	DC to 3 GHz
Impedance	50 Ohms
Max VSWR	1.35:1

Mechanical Specifications

Temperature

Temperature Operating Range	-65 to +165 deg C
-----------------------------	-------------------

Size

Length	60 in [152.4 cm]
Cable Color	Tan

Cable

Description	Cable
Cable Type	RG316
Inner Conductor Type	Solid
Cable Inner Conductor	Copper, Silver
No of Shields	1
Dielectric Type	PTFE
Jacket Material	FEP
Jacket Diameter	0.098 in [2.49 mm]

Connectors

Description	Connector 1	Connector 2
Type	SMA Female	SMC Plug Right Angle
Configuration	Straight	Right Angle
Inner Conductor Material & Plating	Beryllium Copper, Gold	Beryllium Copper, Gold
Inner Conductor Plating Spec.	50μ in. minimum	50μ in. minimum
Hex Size	1/4 inch	1/4 inch
Body Material & Plating	Brass, Gold	Brass, Gold
Body Plating Spec.	3μ in. minimum	3μ in. minimum
Dielectric Type	PTFE	PTFE

Compliance Certifications (visit www.FairviewMicrowave.com for current document)

Notes:

- Values at +25 °C, sea level




Configuration:

- SMA Female
- SMC Plug Right Angle
- RG316

Fairview Microwave
1130 Junction Dr. #100
Allen, TX 75013
Tel: 1-800-715-4396 / (972) 649-6678
Fax: (972) 649-6689
www.fairviewmicrowave.com
sales@fairviewmicrowave.com

Typical Performance Data

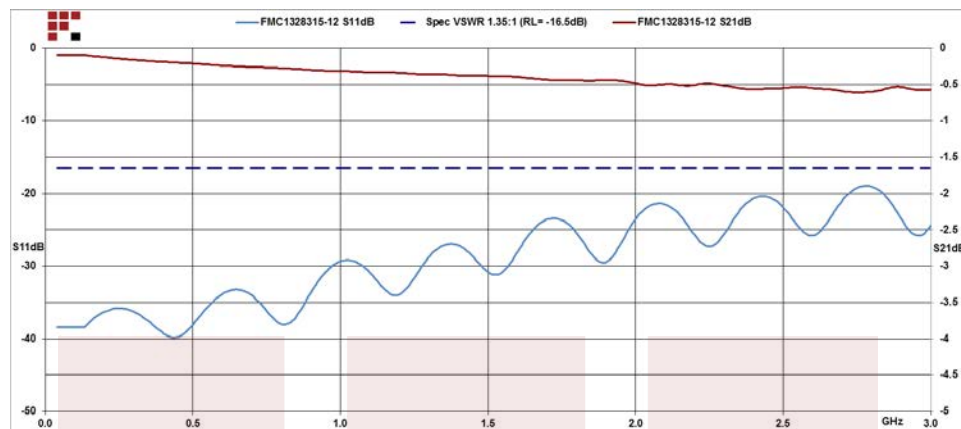

How to Order

Part Number Configuration:

FMC1328315 - xx uu

cm = Centimeters
<blank> = Inches
Length


Example: FMC1328315-12 = 12 inches long cable
FMC1328315-100cm = 100 cm long cable

SMA Female to RA SMC Plug Cable RG-316 Coax in 60 Inch from Fairview Microwave has same day shipment for domestic and International orders. Our RF, microwave and fiber optic products maintain a 99% availability and are part of the broadest selection in the industry.

Click the following link to obtain additional part information: [SMA Female to RA SMC Plug Cable RG-316 Coax in 60 Inch FMC1328315-60](http://www.fairviewmicrowave.com/sma-female-ra-smc-plug-cable-rg316-coax-fmc1328315-60-p.aspx)

URL: <http://www.fairviewmicrowave.com/sma-female-ra-smc-plug-cable-rg316-coax-fmc1328315-60-p.aspx>

The information contained in this document is accurate to the best of our knowledge and representative of the part described herein. It may be necessary to make modifications to the part and/or the documentation of the part, in order to implement improvements. Fairview Microwave reserves the right to make such changes as required. Unless otherwise stated, all specifications are nominal. Fairview Microwave does not make any representation or warranty regarding the suitability of the part described herein for any particular purpose, and Fairview Microwave does not assume any liability arising out of the use of any part or documentation.

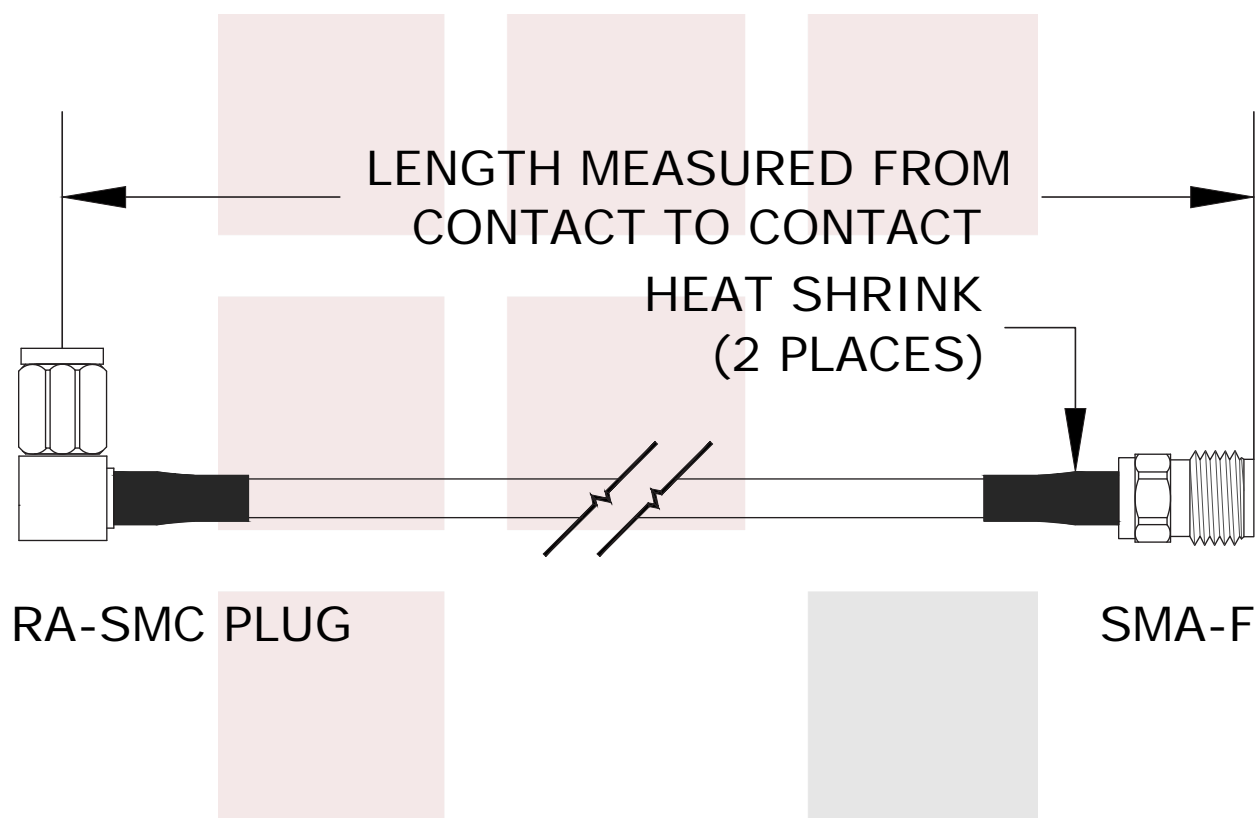

FAIRVIEW MICROWAVE INC. ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM		NOTES: 1. UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE NOMINAL. 2. ALL SPECIFICATIONS ARE SUBJECT TO CHANGE WITHOUT NOTICE AT ANY TIME. 3. DIMENSIONS ARE IN INCHES [mm].			
TITLE SMA Female to RA SMC Plug Cable RG-316 Coax in 60 Inch		DWG NO FMC1328315-XX		CAGE CODE 3FKR5	
CAD FILE	103014	SHEET	SCALE	N/A	SIZE A 5568